


**LOW PROFILE**

**806-960 MHz**

**LP800SMA**

**LP800SMA3**

Series : **ANTENNA**

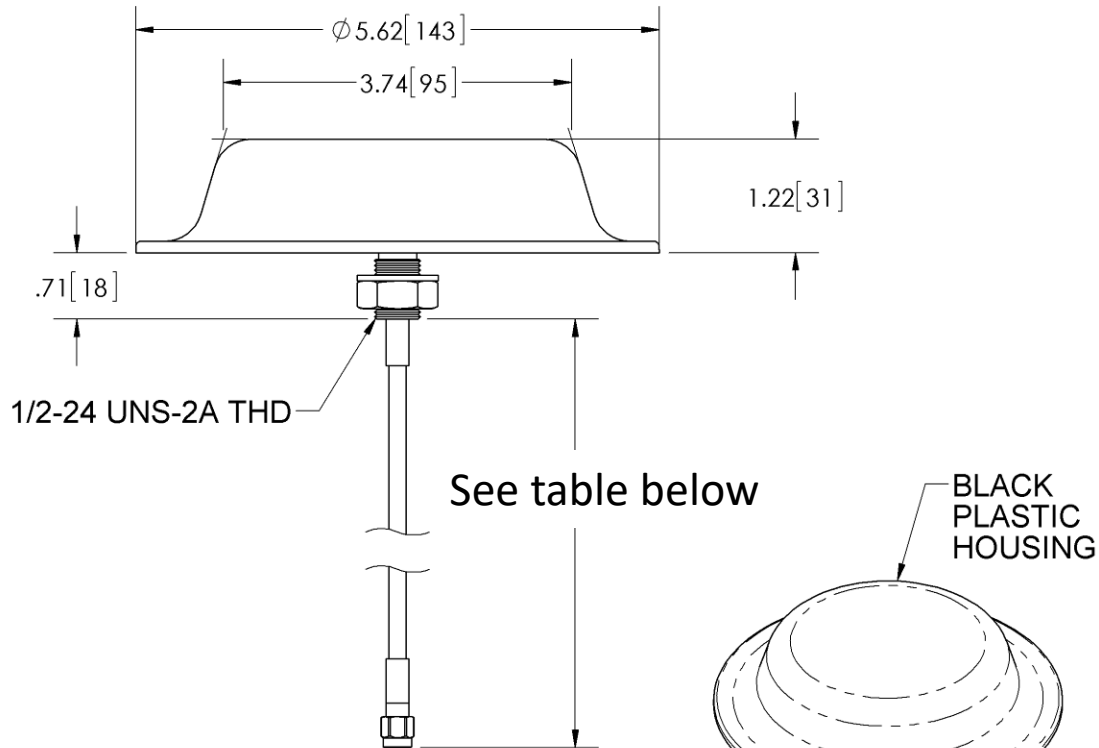

Part Number	Cable Length
LP800SMA	17 ft
LP800SMA3	3 ft

RG-58  
CABLE

SMA  
PLUG

BLACK  
PLASTIC  
HOUSING

All dimensions are in inches (mm)

**Issue: 1118**

In the effort to improve our products, we reserve the right to make changes judged to be necessary.

**CONFIDENTIAL AND PROPRIETARY INFORMATION**

This document contains confidential and proprietary information of Pulse Electronics, Inc. (Pulse) and is protected by copyright, trade secret and other state and federal laws. Its receipt or possession does not convey any rights to reproduce, disclose its contents, or to manufacture, use or sell anything it may describe. Reproduction, disclosure or use without specific written authorization of Pulse is strictly forbidden

**LOW PROFILE**

**806-960 MHz**

**LP800SMA**

**LP800SMA3**

Series : **ANTENNA**

**ELECTRICAL SPECIFICATIONS**

Frequency	806-960	MHz
Nominal Impedance	50	Ω
VSWR	2.1:1	
Gain (Overall gain)	UNITY/2.14	dBi
Bandwidth @ 1.5	8.5%	
Bandwidth @ 2.0	10%	
Connector type:	SMA MALE PLUG	
Cable type:	RG-58	
Length:	17	ft (LP800SMA)
	3	ft (LP800SMA3)
Powerwithstanding	100	Watts

**MECHANICAL SPECIFICATIONS**

Plastic radome:	MACKROBLEND(PC/ABS)
Color:	BLACK
Overall length:	5.63 X 1.22 INCHES
Fixing system:	DIRECT MOUNT, ½ HOLE

**ENVIRONMENTAL SPECIFICATIONS**

Operating temperature	-40/+85 ° C
-----------------------	-------------

**Issue: 1118**

In the effort to improve our products, we reserve the right to make changes judged to be necessary.

**CONFIDENTIAL AND PROPRIETARY INFORMATION**

This document contains confidential and proprietary information of Pulse Electronics, Inc. (Pulse) and is protected by copyright, trade secret and other state and federal laws. Its receipt or possession does not convey any rights to reproduce, disclose its contents, or to manufacture, use or sell anything it may describe. Reproduction, disclosure or use without specific written authorization of Pulse is strictly forbidden

