


5 x 20mm Miniature Glass

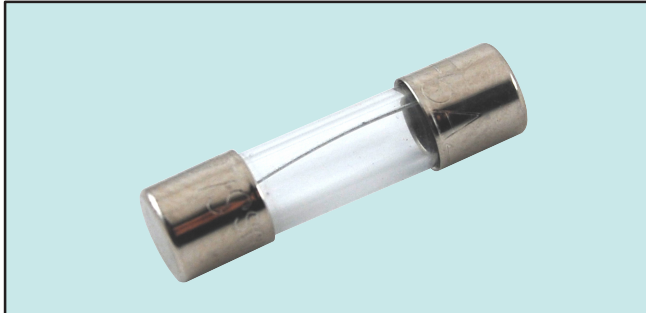


Features

- Available in Fast Acting and Slow Blow Types
- RoHS Compliant



F-02

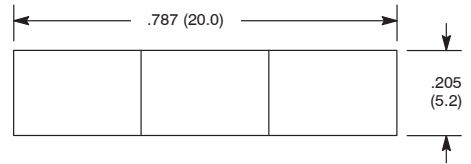

Specifications

Rated Voltage: 125V / 250V

Breaking Capacity: 125VAC, 10KA; 250VAC, 20A

Time Current Characteristics:

% of Ampere Rating	Opening Time	
	Fast Acting	Slow Blow
100%	4 hours min.	4 hours min.
135%	1 hour max.	1 hour max.
200%	5 seconds max.	120 seconds max.

Ordering Information:

	NTE Type No.		Rated Current	Diag No.
	Fast Acting	Slow Blow		
	74-5FG100MA		100mA	F-02
	74-5FG125MA		125mA	F-02
	74-5FG160MA		160mA	F-02
	74-5FG200MA	74-5SG200MA **	200mA	F-02
	74-5FG250MA	74-5SG250MA **	250mA	F-02
		74-5SG300MA **	300mA	F-02
	74-5FG315MA		315mA	F-02
	74-5FG400MA	74-5SG400MA **	400mA	F-02
	74-5FG500MA	74-5SG500MA	500mA	F-02
		74-5SG600MA	600mA	F-02
	74-5FG630MA		630mA	F-02
		74-5SG750MA	750mA	F-02
	74-5FG800MA	74-5SG800MA	800mA	F-02
	74-5FG1A	74-5SG1A	1.0A	F-02
NEW	74-5FG1.25A	74-5SG1.25A	1.25A	F-02
	74-5FG1.5A		1.5A	F-02
	74-5FG1.6A	74-5SG1.6A	1.6A	F-02
	74-5FG2A	74-5SG2A	2.0A	F-02
NEW	74-5FG2.5A	74-5SG2.5A	2.5A	F-02
	74-5FG3A	74-5SG3A	3.0A	F-02
	74-5FG3.15A	74-5SG3.15A	3.15A	F-02
	74-5FG4A	74-5SG4A	4.0A	F-02
NEW	74-5FG5A	74-5SG5A	5.0A	F-02
		74-5SG6A	6.0A	F-02
	74-5FG6.3A	74-5SG6.3A	6.3A	F-02
NEW		74-5SG7A	7.0A	F-02
NEW	74-5FG8A	74-5SG8A	8.0A	F-02
NEW	74-5FG10A	74-5SG10A **	10A	F-02
NEW		74-5SG12.5A	12.5A	F-02
	74-5FG15A		15A	F-02

** Not UL Approved.

Accessories:

Description	NTE Type No.
Fuse Clips (Double Fluted)	74-FC5
Panel Mount Fuse Holder	74-FH5
In-Line Fuse Holder	74-IFH5
Fuse Block w/Clear Cover	74-FB5