


Ratings:
 Current 20A
 Voltage 300 V
 Wire Size 30-12AWG
 Test Voltage 2.0 kV
 Rated Torque / Screw Size 0.5Nm / M3

Rated Cross Section:
 Single Wire (solid) 4.0mm²
 Stranded Wire (flexible) 2.5mm²
 Stranded Wire with Ferrules 2.5mm²

Dimensions:
 Spacing 5.08mm
 PCB Hole Diameter 1.3mm
 Stripped Length 8.0mm

Materials:
 Insulating Material PA
 Flammability UL94V-0
 Temperature -30°C/+105°C
 Block CuZn
 Wire Guard Cu
 Color Green

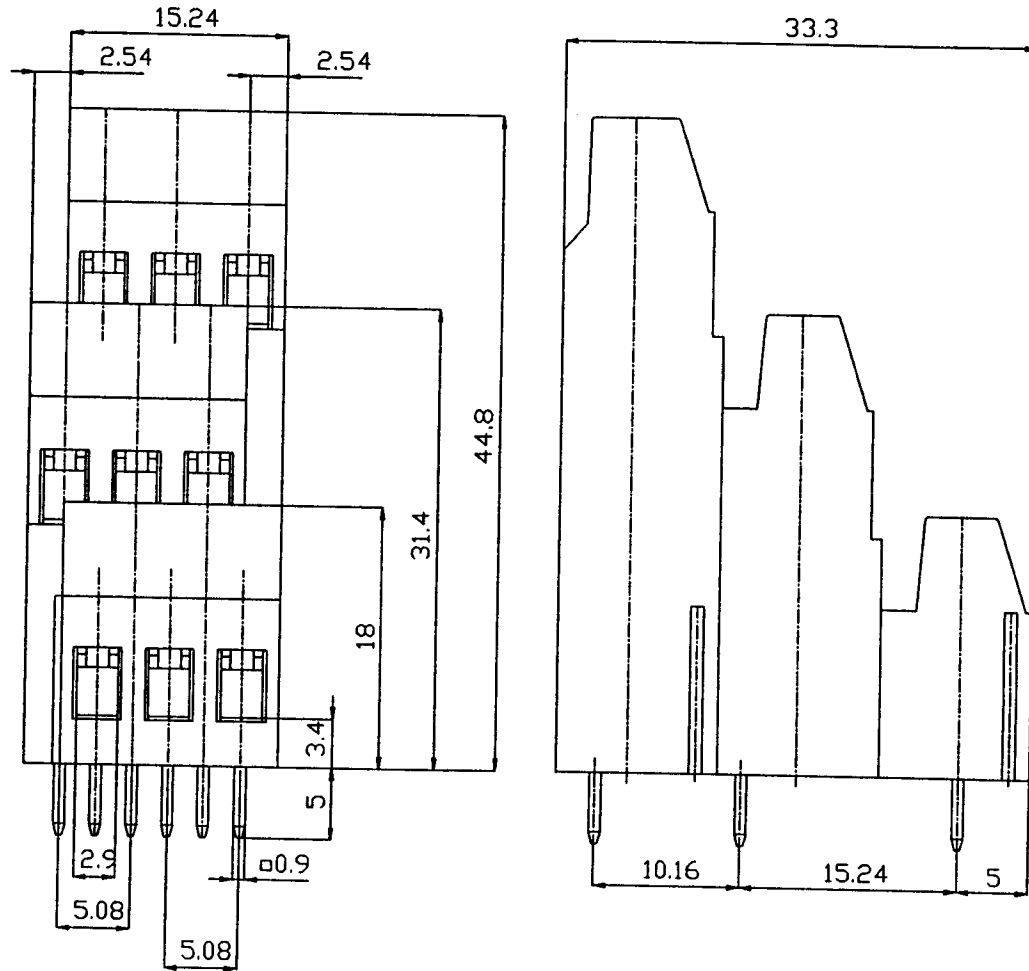

ON-SHORE TECHNOLOGY, INC.

Part Number

EDZ770/ * *

* - NUMBER OF POSITIONS IN ONE ROW

Units

mm

Drawing

Reviewed

Approved

Date

1/6/99

Sheet 1 of 1