 


**SPECIFICATIONS:**

Insulation Resistance: 1,000MΩ min. at 500V DC  
 Withstanding Voltage: 500Vrms for 1min  
 Voltage Rating: 5Vrms AC  
 Current Rating: 0.5A  
 Contact Resistance: 100mΩ max. at 20mV max.  
 Operating Temp.: - 55°C ~ +85°C  
 Mating Cycle: 5,000 times

**PART NUMBER:**

**FMS008-6001-0**




**MATERIALS AND FINISH:**

- Contacts: Ni-Au/SnCu Alloy
- Insulator: LCP
- Metal Shell: Stainless Steel

**FEATURES:**

- Low-profile design (1.50mm H)
- Card-detection switch
- Standard SMT Mount
- RoHS and REACH Compliant

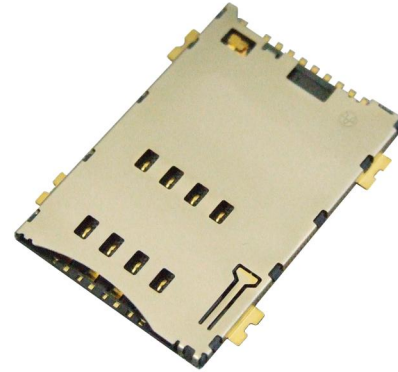

**OUTLINE DIMENSIONS (mm):**

