



Plug-in miniature power relay, With power contact, 1 CO contact, Input voltage: 60 VDC

### Kaufmännische Daten

Artikelnummer	<u>15503.2</u>
Artikelbezeichnung	PRC 1/60V DC
GTIN (EAN)	4044211118167
Packaging unit	10
Quantity unit	PC
Weight per piece (not including packaging)	5 g
Weight per piece (including packaging)	6.38 g
Unit of weight	G
Customs number	85364900
Country of origin	ES
Product description	Plug-in relay

### Technische Daten

#### Dimensions

Length	28 mm
Width	5 mm
Height	15 mm

#### Ratings

Overvoltage category	III
Contamination degree	3 (250 VAC) / 2 (400 VAC)

#### Input data

Working voltage	42-90 VDC -
Holding current	0,4 Un -
Drop-out voltage	0,05 Un
Coil voltage	60 VDC -
Power consumption	0,176 W
Coil resistance	20500 Ohm

#### Output data

Switching voltage / switching voltage max.	250 / 400 VAC
Continuous current max. / Inrush current max.	6 / 10 A
Contact configuration	1 CO contact
Switching capacity, max.	1500 VA
Electrical lifespan (AC1)	60x10 <sup>3</sup>
Mechanical lifespan	10x10 <sup>6</sup>
Contact load, min.	500 mW
Bounce time at close of the NO/NC contact	3/8 ms

#### Materials

Contact material	AgNi
Working temperature, min.	-40 °C
Working temperature, max.	85 °C

#### Further technical data

Degree of protection	RTIII (wash-tight)
Insulation voltage coil/contact	4 kV
Response/release time	12 / 5 ms
Insulation voltage contact/contact	1 kV
Vibration resistance NO/NC	10/5 g
Shock resistance NO/NC	10/5 g

---

### Technische Daten

---

#### Environmental Product Compliance

---

REACH Conform	yes
REACH Reference date	2023-06-14
REACH Candidate Substance Note	No
RoHS Conform	yes

---

---

### Zulassungen

---


#### Standards and regulations

---

CE compliant	yes
--------------	-----


---

### Medien

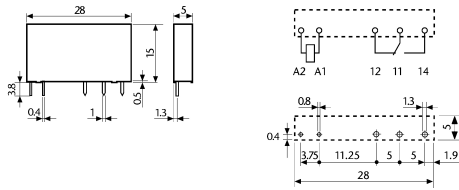

### Zubehör

#### ##INVERSE##CONTA-ELECTRONICS

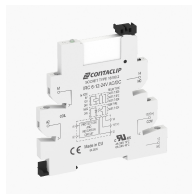

Interface-Relay-Compact (IRC) socket base IRC with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16191.2</u>	IRC 110...125V AC/DC	4044211187279	10 ST




Interface-Relay-Compact (IRC) socket base FIRC with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16211.2</u>	FIRC 110...125V AC/DC	4044211187460	10 ST




Interface-Relay-Compact (IRC) socket base FIRC P with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 60 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16214.2</u>	FIRCP 60V AC/DC	4044211187491	10 ST

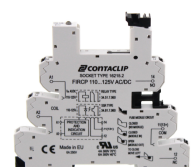


Interface-Relay-Compact (IRC) socket base FIRC P with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16215.2</u>	FIRCP 110...125V AC/DC	4044211187514	10 ST

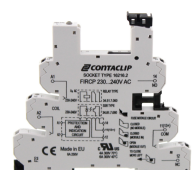

Interface-Relay-Compact (IRC) socket base FIRC P with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16216.2</u>	FIRCP 230...240V AC	4044211187507	10 ST

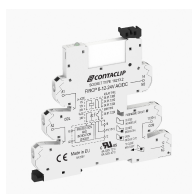

Interface-Relay-Compact (IRC) socket base FIRC P with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VDC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16217.2</u>	FIRCP 110...125V DC	4044211187521	10 ST

### ##INVERSE##CONTA-ELECTRONICS

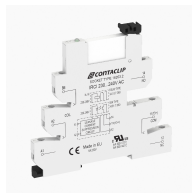


Interface-Relay-Compact (IRC) socket base IRCI with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16202.2</u>	IRCI 110...125V AC/DC	4044211187392	10 ST

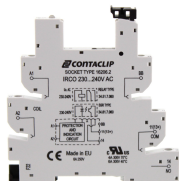


Interface-Relay-Compact (IRC) socket base IRCO with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16206.2</u>	IRCO 230...240V AC	4044211187439	10 ST

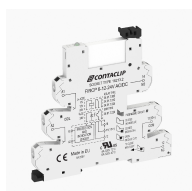


Interface-Relay-Compact (IRC) socket base FIRCP with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 220 VDC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16218.2</u>	FIRCP 220V DC	4044211187538	10 ST

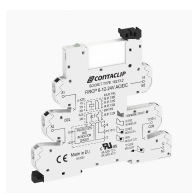

Interface-Relay-Compact (IRC) socket base FIRCP with Push-In connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16219.2</u>	FIRCP LW 110...125V AC/DC	4044211187545	10 ST

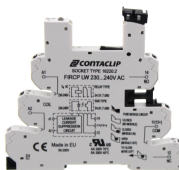

Interface-Relay-Compact (IRC) socket base FIRCP with Push-In connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16220.2</u>	FIRCP LW 230...240V AC	4044211187552	10 ST



Interface-Relay-Compact (IRC) socket base FIRCI with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16222.2</u>	FIRCI 110...125V AC/DC	4044211187576	10 ST

### ##INVERSE##CONTA-ELECTRONICS

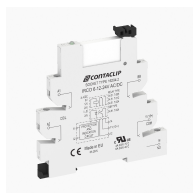


Interface-Relay-Compact (IRC) Complete, Consisting of base IRCO... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16253.2</u>	IRCOU 1/125V AC/DC	4044211200350	10 ST

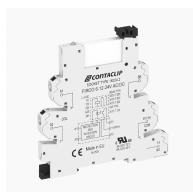


Interface-Relay-Compact (IRC) socket base FIRC O with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16225.2</u>	FIRCO 110...125V AC/DC	4044211187606	10 ST

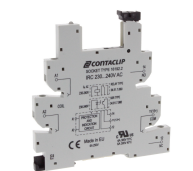


Interface-Relay-Compact (IRC) socket base IRC with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16192.2</u>	IRC 230...240V AC	4044211187286	10 ST

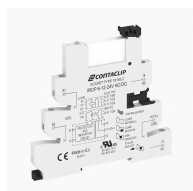


Interface-Relay-Compact (IRC) socket base IRCP with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 60 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16194.2</u>	IRCP 60V AC/DC	4044211187309	10 ST

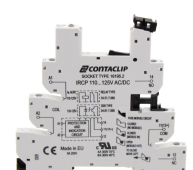

Interface-Relay-Compact (IRC) socket base IRCP with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16195.2</u>	IRCP 110...125V AC/DC	4044211187316	10 ST

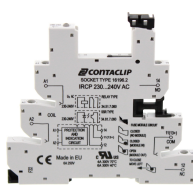


Interface-Relay-Compact (IRC) socket base IRCP with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16196.2</u>	IRCP 230...240V AC	4044211187323	10 ST



### ##INVERSE##CONTA-ELECTRONICS

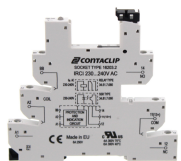


Interface-Relay-Compact (IRC) socket base IRCI with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16203.2</u>	IRCI 230...240V AC	4044211187408	10 ST




Interface-Relay-Compact (IRC) socket base IRCO with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16205.2</u>	IRCO 110...125V AC/DC	4044211187422	10 ST

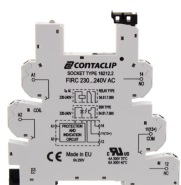


Interface-Relay-Compact (IRC) socket base FIRC with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16212.2</u>	FIRC 230...240V AC	4044211187477	10 ST

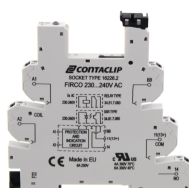


Interface-Relay-Compact (IRC) socket base FIRC O with Push-In connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16226.2</u>	FIRCO 230...240V AC	4044211187613	10 ST

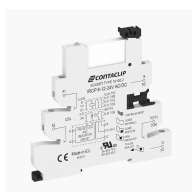

Interface-Relay-Compact (IRC) socket base IRCP with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VDC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16197.2</u>	IRCP 110...125V DC	4044211187347	10 ST

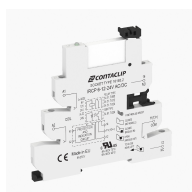

Interface-Relay-Compact (IRC) socket base IPRC with screw connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16200.2</u>	IRCP LW 230...240V AC	4044211187378	10 ST

### ##INVERSE##CONTA-ELECTRONICS

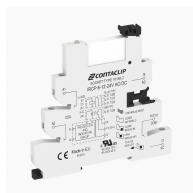


Interface-Relay-Compact (IRC) socket base IPRC with screw connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16199.2</u>	IRCP LW 110...125V AC/DC	4044211187361	10 ST

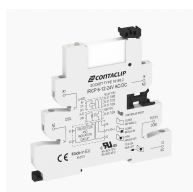


Interface-Relay-Compact (IRC) socket base IPRC with screw connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16200.2</u>	IRCP LW 230...240V AC	4044211187378	10 ST

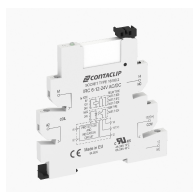


Interface-Relay-Compact (IRC) Complete, Consisting of base IRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16233.2</u>	IRCU 1/125V AC/DC	4044211200176	10 ST

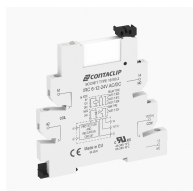

Interface-Relay-Compact (IRC) Complete, Consisting of base IRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16234.2</u>	IRCU 1/240V AC	4044211200183	10 ST

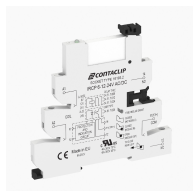

Interface-Relay-Compact (IRC) Complete, Consisting of base IRCP... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 60 VAC/DC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16238.2</u>	IRCPU 1/60V AC/DC	4044211200220	10 ST



Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 60 VAC/DC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16268.2</u>	FIRCPU 1/60V AC/DC	4044211200473	10 ST

### ##INVERSE##CONTA-ELECTRONICS

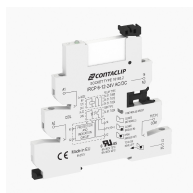


Interface-Relay-Compact (IRC) Complete, Consisting of base IRCP... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16240.2</u>	IRCPU 1/240V AC	4044211200244	10 ST

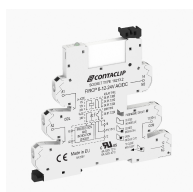


Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16270.2</u>	FIRCPU 1/240V AC	4044211200497	10 ST

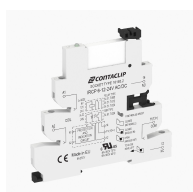


Interface-Relay-Compact (IRC) Complete, Consisting of base IRCP... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 220 VDC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16242.2</u>	IRCPU 1/220V DC	4044211200268	10 ST

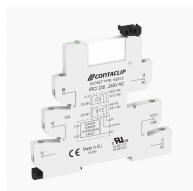

Interface-Relay-Compact (IRC) Complete, Consisting of base IRCI... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16249.2</u>	IRCIU 1/240V AC	4044211200336	10 ST

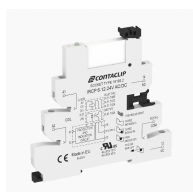

Interface-Relay-Compact (IRC) Complete, Consisting of base IRCP... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16244.2</u>	IRCPU LW 1/240V AC	4044211200282	10 ST



Interface-Relay-Compact (IRC) Complete, Consisting of base IRCO... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16253.2</u>	IRCOU 1/125V AC/DC	4044211200350	10 ST

### ##INVERSE##CONTA-ELECTRONICS

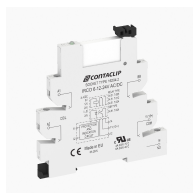

Interface-Relay-Compact (IRC) Complete, Consisting of base IRCO... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16254.2</u>	IRCOU 1/240V AC	4044211200367	10 ST




Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCU... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16263.2</u>	FIRCU 1/125V AC/DC	4044211200428	10 ST




Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCU... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16264.2</u>	FIRCU 1/240V AC	4044211200435	10 ST

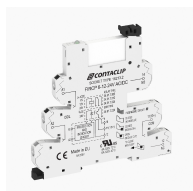


Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 60 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16268.2</u>	FIRCPU 1/60V AC/DC	4044211200473	10 ST

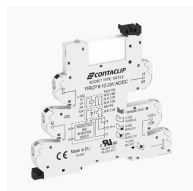

Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16269.2</u>	FIRCPU 1/125V AC/DC	4044211200480	10 ST

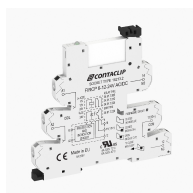

Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16270.2</u>	FIRCPU 1/240V AC	4044211200497	10 ST

### ##INVERSE##CONTA-ELECTRONICS



Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 220 VDC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16272.2</u>	FIRCPU 1/220V DC	4044211200510	10 ST



Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16273.2</u>	FIRCPU LW 1/125V AC/DC	4044211200527	10 ST




Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16274.2</u>	FIRCPU LW 1/240V AC	4044211200534	10 ST



Interface-Relay-Compact (IRC) Complete, Consisting of base IRCI... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16248.2</u>	IRCIU 1/125V AC/DC	4044211200329	10 ST

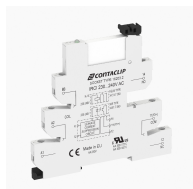

Interface-Relay-Compact (IRC) Complete, Consisting of base IRCI... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16249.2</u>	IRCIU 1/240V AC	4044211200336	10 ST



Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCO... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC


Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16283.2</u>	FIRCOU 1/125V AC/DC	4044211200626	10 ST

### ##INVERSE##CONTA-ELECTRONICS



Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCO... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16284.2</u>	FIRCOU 1/240V AC	4044211200633	10 ST

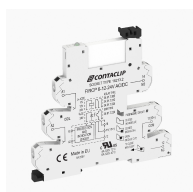


Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCP... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VDC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16271.2</u>	FIRCPU 1/125V DC	4044211200503	10 ST



Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCI... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16278.2</u>	FIRCIU 1/125V AC/DC	4044211200572	10 ST

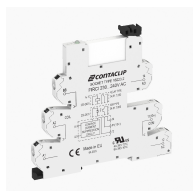

Interface-Relay-Compact (IRC) Complete, Consisting of base FIRCI... with Push-In connection and pluggable miniature relay with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16279.2</u>	FIRCIU 1/240V AC	4044211200589	10 ST



Plug-Relay-Compact (PRC) socket base PRC with tension-spring connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 220 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15493.2</u>	ZPRC 220...240V AC/DC	4044211118334	10 ST



Plug-Relay-Compact (PRC) socket base PRC with screw connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15555.2</u>	PRC LW 110...125V AC/DC	4044211118280	10 ST

### ##INVERSE##CONTA-ELECTRONICS



Plug-Relay-Compact (PRC) socket base PRC with tension-spring connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15556.2</u>	ZPRC LW 110...125V AC/DC	4044211118358	10 ST



Plug-Relay-Compact (PRC) socket base PRC with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 230 to 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>16145.2</u>	PRC 230...240V AC	4044211189532	10 ST



Plug-Relay-Compact (PRC) socket base PRC with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 220 to 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15489.2</u>	PRC 220...240V AC/DC	4044211118259	10 ST



Plug-Relay-Compact (PRC) socket base PRC with screw connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 220 to 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15491.2</u>	PRC LW 220...240V AC	4044211118273	10 ST



Plug-Relay-Compact (PRC) socket base PRC with tension-spring connection and residual current suppression for long cables, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 220 to 240 VAC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15495.2</u>	ZPRC LW 220...240V AC	4044211118365	10 ST



Plug-Relay-Compact (PRC) socket base PRC with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 48 or 60 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15496.2</u>	PRC 48-60V AC/DC	4044211118235	10 ST

### ##INVERSE##CONTA-ELECTRONICS



Plug-Relay-Compact (PRC) socket base PRC with screw connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15497.2</u>	PRC 110...125V AC/DC	4044211118242	10 ST



Plug-Relay-Compact (PRC) socket base PRC with tension-spring connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 648 or 60 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15498.2</u>	ZPRC 48-60V AC/DC	4044211118303	10 ST



Plug-Relay-Compact (PRC) socket base PRC with tension-spring connection, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 110 to 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15499.2</u>	ZPRC 110...125V AC/DC	4044211118327	10 ST



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 60 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15510.2</u>	PRCU 1/60V AC/DC	4044211118495	10 ST



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with tension-spring connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15552.2</u>	ZPRCU LW 1/240V AC	4044211118679	10 ST



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15511.2</u>	PRCU 1/125V AC/DC	4044211118501	10 ST



### ##INVERSE##CONTA-ELECTRONICS



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15554.2</u>	PRCU LW 1/240V AC	4044211118563	10 ST



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 60 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15521.2</u>	ZPRCU 1/60V AC/DC	4044211118600	10 ST



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15522.2</u>	ZPRCU 1/125V AC/DC	4044211118617	10 ST



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15554.2</u>	PRCU LW 1/240V AC	4044211118563	10 ST



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15553.2</u>	PRCU LW 1/125V AC/DC	4044211118556	10 ST



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 125 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15522.2</u>	ZPRCU 1/125V AC/DC	4044211118617	10 ST

### ##INVERSE##CONTA-ELECTRONICS



Plug-Relay-Compact (PRC) Complete, Consisting of base PRC... with screw connection and pluggable miniature relay PRC... with power contact, Mounting type: Mounting rail TS 35, 1 CO contact, Input voltage: 240 VAC/DC

Artikelnummer	Artikelbezeichnung	GTIN (EAN)	VPE
<u>15554.2</u>	PRCU LW 1/240V AC	4044211118563	10 ST