



P.C.B. LAYOUT

Material

Terminal body (metal housing): Brass(CuZn)
 Terminal screw: Steel Zinc plating "-" slot type
 Contacts: Brass
 Surface of solder tail: Tin plated
 Insulator (housing): Thermoplastic (UL94V-0), Green

Electrical

Voltage rating: 300VAC
 Current rating: 20A
 Solid wire(AWG): 12-30
 Stranded wire(AWG): 12-30
 Torque(Lb-in): 3.5
 Screw: M3
 Wire strip length: 6-7mm
 Withstanding Voltage: 1.6KV
 Operating temperature: -40°C to +115°C
 Soldering temperature: 250°C±10°C/5 Sec
 Safety Approval: US

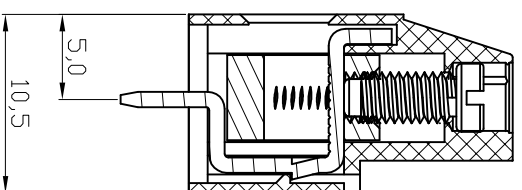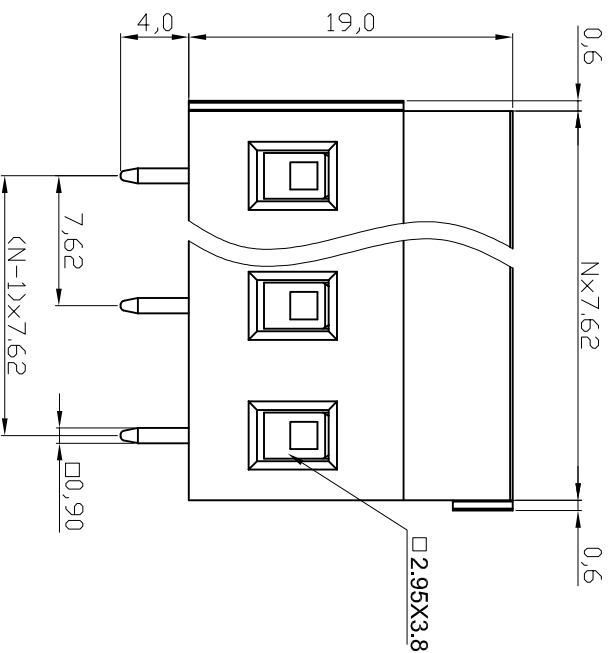

N=Number of contacts

RoHS compliant

 File No.: E349947

| | | | | | | | |
|-----------|-------|--|--|--|----------|------------|--------|
| Scale | 1:1 | | | | | | |
| TOLERANCE | | | | | | | |
| X. | ±0.50 | | | | Drawn | 29.07.2009 | Dean |
| X.X | ±0.30 | | | | Approved | 19.04.2016 | Winnie |
| X.XX | ±0.10 | | | | | | |
| DIM | TOL | | | | | | |
| X. ° | ±1° | | | | | | |
| X.X° | ±X° | | | | | | |
| Angle | TOL | | | | | | |

| | | | | | |
|-----------------|--|--|--|--|--|
| Customer-No. | | | | | |
| ASSMANN WSW-No. | | | | | |
| A-TB762-VJXH | | | | | |
| Drawing-No. | | | | | |
| ASS 3596 CO | | | | | |
| rev02 | | | | | |
| Replace | | | | | |
| Sheet | | | | | |



1 2 3 4 5 6 7

SVXXXX