
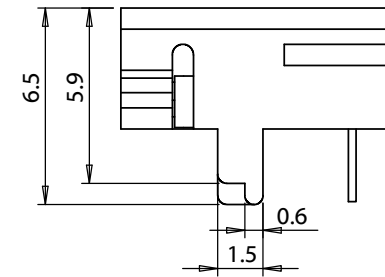
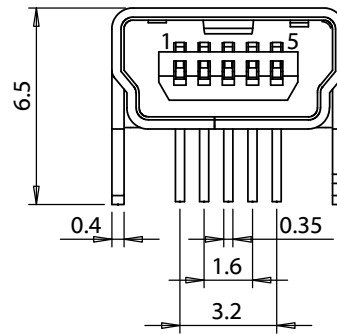
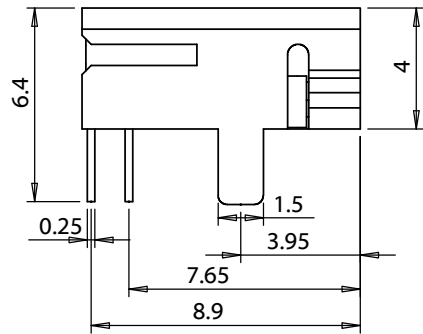
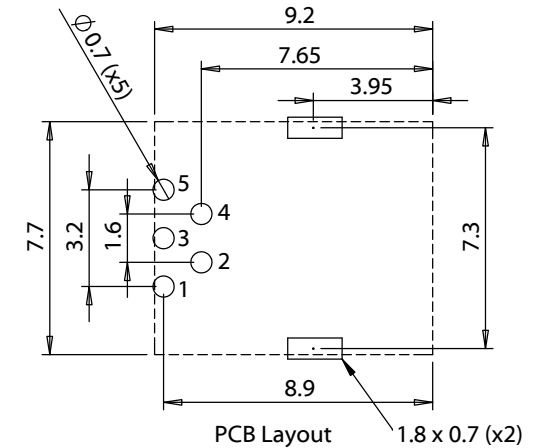
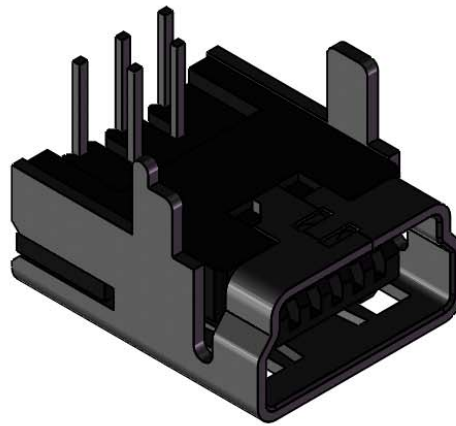



# USB mini B jack 90° PCB mount

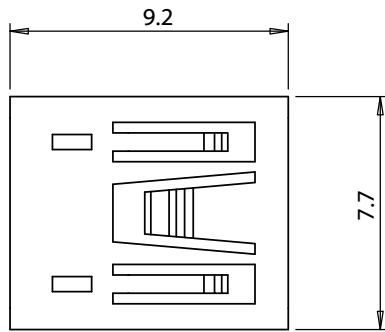

Revision:	Date:	Description:	Prepared:	Notes:	<b>TENSILITY</b> tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com	
A	09/28/2015	Initial release	Verified:			RoHS and REACH compliant
A1	02/16/2016	Corrected part description	Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Function test: no open, no short circuit, no intermittent	Size: Part number: A 54-00027	
A2	07/30/2018	Corrected operating temp range		Description: Connector, USB mini B Jack, PCB mount, 90°, DIP, black insulator, tube		Scale: 4:1
						Sheet 1 of 2

5

↑

4

3

2

1

