
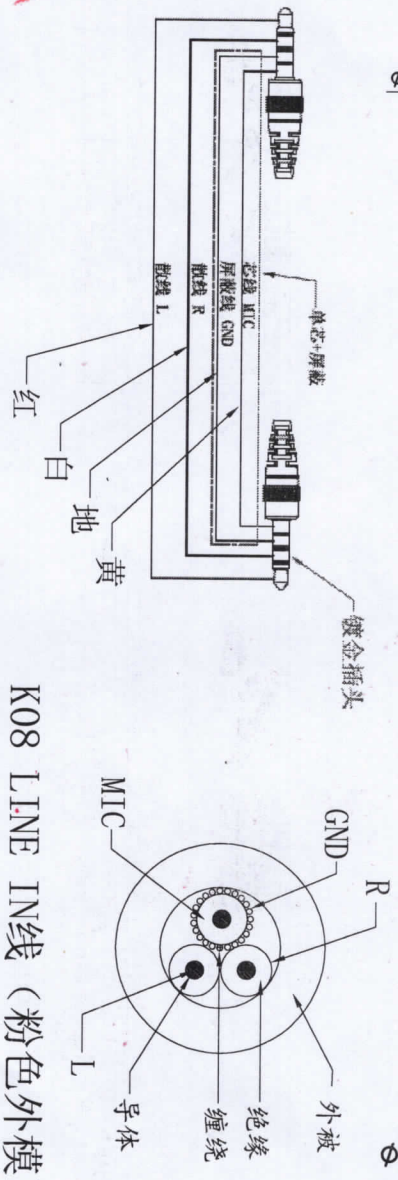
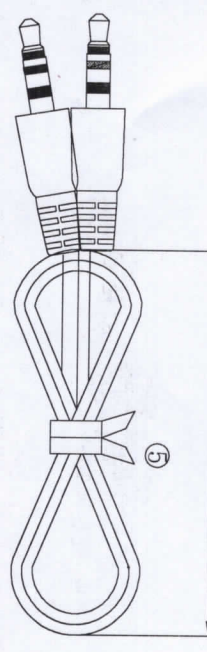


This document is the property of Metek Corporation and is delivered on the express condition that it is not to be disseminated, reproduced or used in whole or in part, for manufacture, production, sale, or other than intended by Metek Corporation without its prior consent, and that no right is granted to disclose or to use any information contained herein, in any form, without the prior written consent of Metek Corporation. The marking on this product doesn't contain environmental hazardous materials per Material Specification or per directive 2002/95/EC for RoHS compliant.
MFG CODE: VXXXX1

REVISIONS		DATE	APPROVED
AX1	NON-RELEASE REVISION		

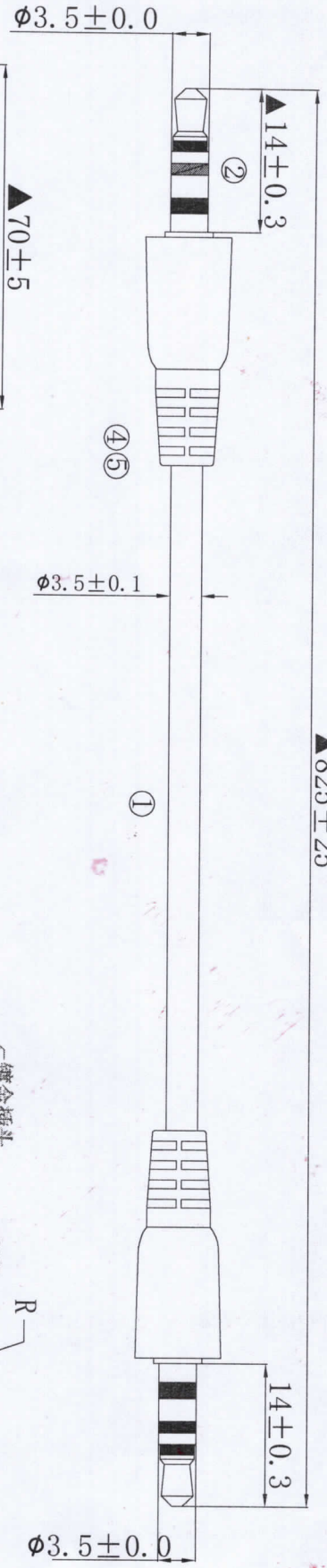

受控文件章

K08 LINE IN线 (粉色外模)

- 技术要求:
- 100%短断开路测试;
 - 导体电阻: 2 Ohm (MAX);
 - 绝缘电阻: DC 300V 2M ohm (Min);
 - 外观不可有刮伤, 缩水, 变形等现象
 - 拉力测试距离200mm, 速度25m/min, 施加5kg力, 保持60s;
 - 推头/SR摇摆: 吊重200g, 角度±45, 速度20次/分钟, 摇摆次数≥500次;
 - 插头与母座插拔, 速度30min测试前0.5~2kgf, 测试后0.5~2kgf, 插拔次数≥2000次.
 - 盐雾试验: 5% NaCl 盐雾 12H, 无锈蚀;
 - ▲符号为重IQC重点检查尺寸
 - 符合RoHS 2.0
 - 放入防水PE袋, 整箱整数包装。

7	纸箱	1/1000	B1-011001	纸箱 46*30*30
6	PE袋	1/1000	B3-071003	PE袋 大113*105*0.03cm
5	扎带	1PCS	H4-100000	白色扎带带铁芯L=100mm
4	外模胶料	8g	J2-351136	35P PVC 插头料 深粉色 RoHS 2.0
3	内模胶料	2g	J4-111105	0405 LDPE胶料 RoHS 2.0
2	插头	2PCS	C1-221107	DC3.5*4.5*24.5MM四极插头镀金
1	Cable	0.80M	X1-358810	音频线7/0.1*1C (26/0.10缠绕) +7/0.1*2C 白色PVC外被 OD: 3.5
0	DESCRIPTION	QTY.	PART NUMBER	DETAIL

TOLERANCE		APPROVALS		DATE		TITLE	
X	±0.30	NAME	DATE	DATE	TITLE	UNIT	SIZE
XX	±0.20	Alex	06/15/2018		伴奏线镀金四极头OD3.5白色	mm	A4
XXX	±0.10				线材外模0.8米		
XXXX							
ANGULAR	±1'	APPROVED		2019/11/05			
UNLESS OTHERWISE SPECIFIED		ENG DWG	PHD				

METEK

东莞市讯联电子有限公司

DEAB014004

AX1