



# 1.View and size(视图及尺寸)

 
| Main technical indicators(主要技术指标) |   |
|-----------------------------------|---|
| 1.Mating (插拔次数)                   | > 3000  |
| 2.Working Temperature (温度)        | -55~+150 °C   |
| 3.IP Rating (防护级别)                | IP66/IP68   |
| 4. 振动                             | 10z 2000z, acceleration 147m / S2, instantaneous break ≤ 1US/10z2000z加速度 147m/S2, 瞬断≤1Us                              |
| 5. 盐雾                             | 5% NaCl for 48 hours/5%NaCl雾气中 48小时   |
| 6. 冲击                             | 980m / S2, instantaneous ≤ 1 US, insulation resistance: > 3000 Ω (normal state)/980m/S2,,瞬间 ≤1 Us 绝缘电阻: > 3000 Ω (常态) |
| 7.Diameter of socket end(插合端直径)   | ∅0.9  |
| 8.Testing Voltage (测试电压)          | 1350V   |
| 9.Working Voltage (工作电压)          | 1450V   |
| 10.Rated Current (额定电流)           | 10A   |
| 11.Shell material(壳体材质)           | Brass (chromium plating) shell and chuck nut/( nickel plating) pin sleeve and middleware/黄铜(镀铬)外壳和夹头螺母/(镀镍)插销套和中间件    |
| 12.Pin Material(插针材料)             | Copper alloy gold plating(铜合金镀金)  |
| 13.Insulator material(绝缘体材质)      | PPS   |

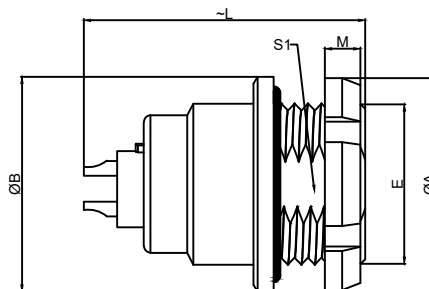


|    | A    | B    | L    | M    | E     | S1   |
|----|------|------|------|------|-------|------|
| MM | 20   | 20   | 27.0 | 3.5  | M16*1 | 14.5 |
| in | 0.79 | 0.79 | 1.06 | 0.14 |       | 0.57 |

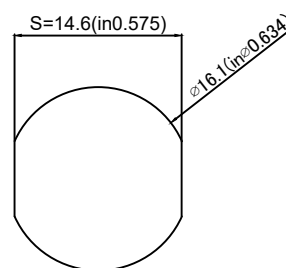

Pane hole size (面板开孔尺寸)



(Welded mother adhesive core) 焊接型母胶芯

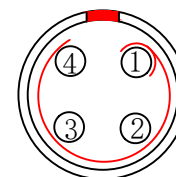

Welded surface (焊接面)

**ZE G.1K.P04.C L L**

- Model(型号)
- Positioning pin(定位销)
- Series(系列)
- Needle core configuration(针芯配置)
- Outer casing(外壳)
- Insulator(绝缘体)
- Needle core(针芯)

| Sum up(总结)                  |  |
|-----------------------------|--|
| Series(系列)                  | K  |
| Shell style/model (外壳样式/型号) | ZEG: Fixed receptacle, nut fixing (back panel mounting)/固定插座, 螺母固定(背板安装) |
| Button (按键)                 | A button(一个按键)   |
| Termination type (终止类型)     | Mother solder tin(母焊锡)   |
| Line diameter awg(线材直径)     | 30-22AWG   |
| Cable diameter∅ (电缆直径)      | 0-0  |
| Matching parts(配件)          | TGG.1K.P04.CLAC45H   |

|        | A      | B      | C√     | ANGLE   |       |
|--------|--------|--------|--------|---------|-------|
| 5-10   | ±0.02  | ±0.05  | ±0.1   | 0°-30°  | ±0.1° |
| 50-100 | ±0.1   | ±0.15  | ±0.2   | 61°-90° | ±0.5° |
| 50-100 | ±0.15  | ±0.2   | ±0.25  |         |       |
| 100-   | ±0.15% | ±0.20% | ±0.25% |         |       |

|                                  |  |          |                                      |               |          |  |
|----------------------------------|--|----------|--------------------------------------|---------------|----------|--|
| DESIGNED (设计)                    |  | DATE(日期) |                                      | SCALE(比例)     | N/A(不适用) | MODEL TYPE<br>型号类型: ZEG.1K.P04.CLL     |
| CHECKED (校对)                     |  | DATE(日期) |                                      | VIEW(视图)      |          | PART NO. 1K4-core socket<br>名称: 1K4芯插座 |
| APPROVED (审核)                    |  | DATE(日期) |                                      | UNIT(单位)      | MM       | DWG NO.:                               |
| REVISIONS                        |  |          |                                      | MATERIAL (材料) |          |  |
| www.helloxkb.com www.helloxkb.cn |  |          | XKB INDUSTRIAL PRECISION CO.,LIMITED |               |          | WEIGHT(重量) SHEET(表) REVISION(修订)       |
|                                  |  |          |                                      |               |          | 1/1 A0                                 |