


- High Common Mode Impedance at High Frequency.
- Excellent Noise Suppression Performance.
- Small Size and Low Profile, Surface Mount Type.
- Operating Temperature Range: -40°C to +85°C.
- RoHS Compliant.




## Electrical Specifications @25°C

Part Number	Common Mode Impedance	DC Resistance	Rated Current	Rated Volt	Insulation Resistance
	$\Omega$ , @100MHz	$\Omega$ Max	mA Max	Vdc Max	M $\Omega$ Min
CC2012A-751	750 $\pm$ 25%	0.88	300	50	10


## MECHANICAL DIMENSIONS (unit:mm)

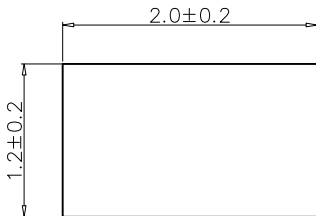


TOP VIEW

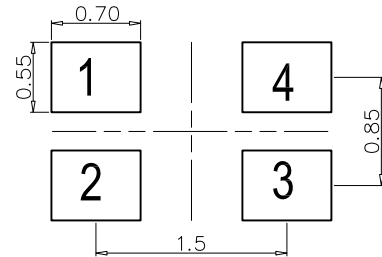

SUGGEST LAYOUT

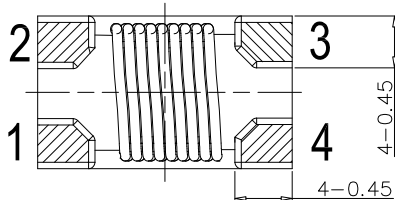


BOTTOM VIEW

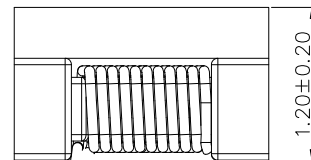

SIDE VIEW

Unless otherwise specified all tolerances are:  $\pm 0.25$ mm

## SCHEMATIC

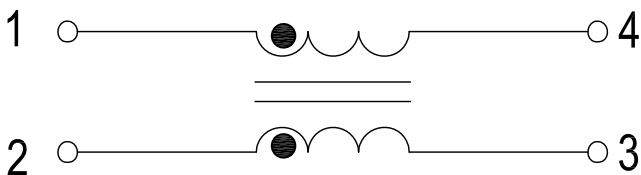

## Impedance Frequency

