

PROTECTIVE CAPS

For any receptacle, we have a cap solution



Description

Protect your plugs and receptacles against dust, water, moisture, EMI.

Main Features

Protective caps for:

- 38999 Series I, II, III (MIL-DTL-38999/EN3645)
- 26482/PT/451 Series (MIL-DTL-26482)
- RJ Field & USB Field

...with many benefits:

- Time & Cost Saving with quick delivery (4 weeks max)
- A large range of caps & receptacles with Black Zinc Nickel and QPL qualified plating available




Rubber Standard Caps NEW

(for 26482 & 38999)



Composite Self-Closing Caps NEW

(for 26482)

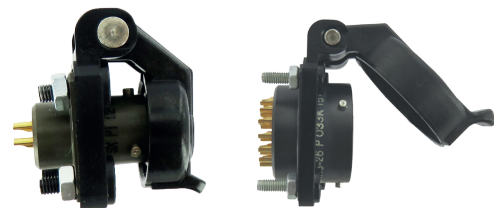


Metallic Standard Caps

(for 26482 & 38999)



Metallic Self-Closing Caps NEW

(for 38999)

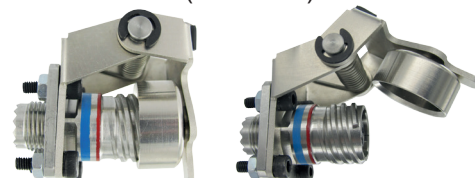

Markets & Applications



Ground Vehicle



Commercial Aerospace



Missile





Industrial




Applications:

- › I/O connectors for boxes
- › Communication systems on the field
- › Various embedded equipment

PROTECTIVE CAPS

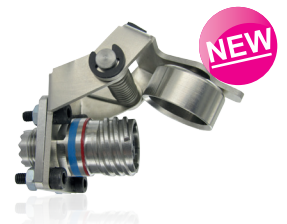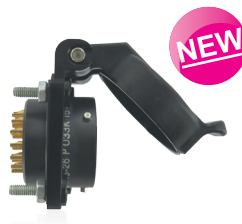

	Rubber Standard Caps	Composite Self-Closing Caps	Metallic Standard Caps	Metallic Self-Closing Caps
Availability	• Available & New	• Available & New	• Available	• Available & New
Compatibility	<ul style="list-style-type: none"> • 38999 Series I, II, III (MIL-DTL-38999/EN3645) • PT/451 Series (MIL-DTL-26482) • RJ Field & USB Field • Amphenol Sine RT360 	<ul style="list-style-type: none"> • PT/451 Series (MIL-DTL-26482) • RJ Field • Amphenol Sine RT360 	<ul style="list-style-type: none"> • 38999 Series I, II, III (MIL-DTL-38999/EN3645) • PT/451 Series (MIL-DTL-26482) • RJ Field & USB Field 	<ul style="list-style-type: none"> • 38999 Series III (MIL-DTL-38999/EN3645) • RJ Field & USB Field
Types	All receptacles	Square Flange receptacles only	All receptacles & plugs	All receptacles
Sizes	6 Sizes available : <ul style="list-style-type: none"> • TV : 9, 11, 13, 15, 17, 19 • PT : 10, 12, 14, 16, 18, 20 	6 Sizes available : <ul style="list-style-type: none"> • PT : 8, 10, 12, 14, 16, 18 	9 Sizes available : <ul style="list-style-type: none"> • TV : 9, 11, 13, 15, 17, 19, 21, 23, 25 • PT : 8, 10, 12, 14, 16, 18, 20, 22, 24 	Sizes available : <ul style="list-style-type: none"> • Square flange : 9, 11, 13, 15, 17, 19 • Jam nut : 15, 19
IP	• IP67 (1m, 30 min sealing)	• IP54 (splash proof)	• IP68 (permanent sealing)	• IP67 (1m, 30 min sealing)
Materials/Plating	• Silicone 200°C	• Composite 125°C	<ul style="list-style-type: none"> • Aluminum <u>Plating:</u> Electroless Nickel, O.D Cadmium, Black Zinc Nickel, Green Zinc Nickel • Stainless Steel <u>Plating:</u> Nickel, Passivated • Bronze 	<ul style="list-style-type: none"> • Aluminum <u>Plating:</u> Electroless Nickel, O.D Cadmium, Black Zinc Nickel, Black Painted
Protection against	 	 	   	   

Link

Rubber Standard Caps

- Nylon cord

Metallic Standard Caps*

- Nylon cord
- Stainless steel rope
- Metallic chain

* All combinations are not available, please consult us.

Termination

For both Rubber & Metallic Standard Caps

- For 07 shell type



- For 00, 02 shell types



- For 01, 06, 08 shell types

