


High Common Mode Impedance at High Frequency.  
 Excellent Noise Suppression Performance.  
 Small Size and Low Profile, Surface Mount Type.  
 Operating Temperature Range: -40°C to +85°C.  
 RoHS Compliant.




**Electrical Specifications @25°C**

Part Number	Common Mode Impedance	DC Resistance	Rated Current	Rated Volt	Insulation Resistance
	$\Omega$ , @100MHz	$\Omega$ Max	mA Max	Vdc Max	M $\Omega$ Min
CC2012A-900	90 $\pm$ 25%	0.35	350	50	10


**MECHANICAL DIMENSIONS (unit:mm)**

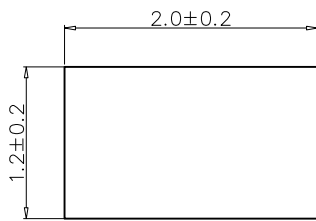


TOP VIEW

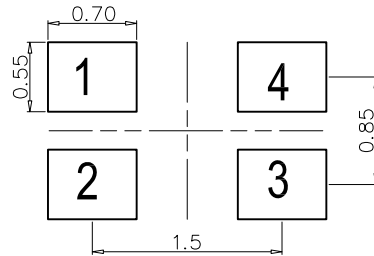

SUGGEST LAYOUT

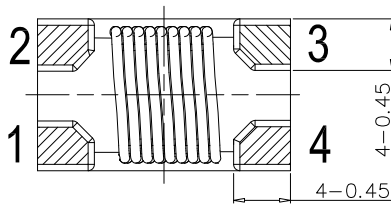

BOTTOM VIEW

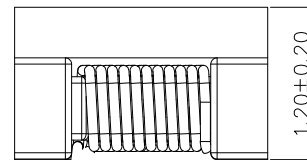

SIDE VIEW

Unless otherwise specified all tolerances are:  $\pm 0.25$ mm

**SCHEMATIC**

