

SUMMARY

Wires

Coax 1



Image is for illustrative purpose only

Series 01
Termination type Male solder
IP rating 50
AWG wire size 0.00 - 0.00
Cable Ø 0.00 - 0.00 mm
Status Active
Matching parts [ECP.01.250.DLL](#)

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model FFS*: Straight plug for cable crimping
Keying Circular, male
Housing Material Brass (gold plated [ISO 27874]) shell, collet nut, brass latch sleeve and mid pieces
Weight 1.31 g

Performance

Configuration 01.250 : 1 Coax (50 Ohm)
Insulator
Rated Current


Specifications

Contact Type: Solder

Others

Endurance (Shell): 1000 mating cycles

DRAWINGS

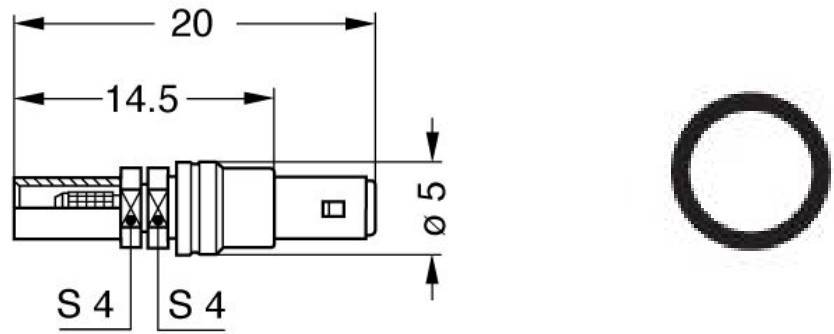

Dimensions

	A	L	M	S1	S2
mm.	5	20	14.5	4	4
in.	0,20	0,79	0,57	0,16	0,16

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.