

3.6 x 10mm Glass Microfuse, Fast Acting




Features

- RoHS Compliant



F-01

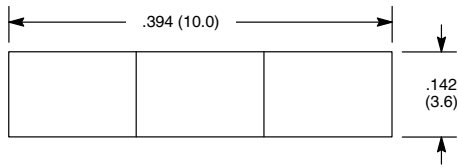

Specifications

Rated Voltage: 125V / 250V

Breaking Capacity: 125VAC, 50A; 250VAC, 50A

Time Current Characteristics:

% of Ampere Rating	Opening Time
110%	4 hours min.
150%	10 minutes max.
200%	5 seconds max.

Ordering Information:

NTE Type No. (Note 1)	Rated Current	Diag No.
74-3FG100MA	100mA	F-01
74-3FG125MA	125mA	F-01
74-3FG1A	1.0A	F-01
74-3FG2A	2.0A	F-01
74-3FG2.5A	2.5A	F-01
74-3FG3A	3.0A	F-01
74-3FG4A	4.0A	F-01
74-3FG5A	5.0A	F-01

Accessories:

Description	NTE Type No.
Fuse Clips	74-FC3

3.6 x 10mm Glass Microfuse, Slow Blow




Features

- RoHS Compliant



F-01

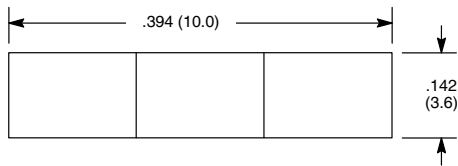

Specifications

Rated Voltage: 125V / 250V

Breaking Capacity: 125VAC, 50A; 250VAC, 50A

Time Current Characteristics:

% of Ampere Rating	Opening Time
110%	4 hours min.
150%	10 minutes max.
200%	120 seconds max.

Ordering Information:

NTE Type No. (Note 1)	Rated Current	Diag No.
74-3SG500MA	500mA	F-01
74-3SG800MA	800mA	F-01
74-3SG1A	1.0A	F-01
74-3SG1.25A	1.25A	F-01
74-3SG2A	2.0A	F-01
74-3SG2.5A	2.5A	F-01
74-3SG3A	3.0A	F-01
74-3SG4A	4.0A	F-01
74-3SG5A	5.0A	F-01
74-3SG6A	6.0A	F-01

Accessories:

Description	NTE Type No.
Fuse Clips	74-FC3