


# NON-INSULATED MALE DISCONNECTS

## Specifications

- **Terminal Material:** Brass
- **Plating:** Electro Tin Plated

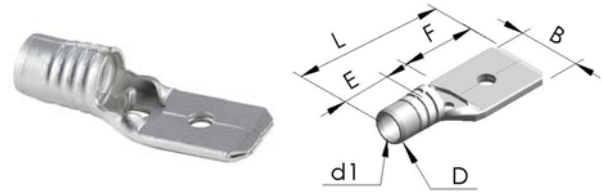

## Ordering Information:

	Wire Range AWG / mm <sup>2</sup>	NTE Part Number	Dimensions inch(mm)						
			NEMA Tab	B	L	F	E	D	d1
NEW	22 – 18 AWG 0.5 – 1.5mm <sup>2</sup>	76-MD22-110	.032 x .110 (0.8 x 2.8)	.110 (2.8)	.610 (15.5)	.307 (7.8)	.197 (5.0)	.106 (2.7)	.067 (1.7)
NEW		76-MD22-187	.032 x .187 (0.8 x 4.8)	.187 (4.8)	.610 (15.5)	.307 (7.8)	.197 (5.0)	.106 (2.7)	.067 (1.7)
NEW		76-MD22	.032 x .250 (0.8 x 6.4)	.250 (6.4)	.638 (16.2)	.307 (7.8)	.197 (5.0)	.106 (2.7)	.067 (1.7)
NEW	16 – 14 AWG 1.5–2.5mm <sup>2</sup>	76-MD16-110	.032 x .110 (0.8 x 2.8)	.110 (2.8)	.610 (15.5)	.307 (7.8)	.197 (5.0)	.130 (3.3)	.091 (2.3)
NEW		76-MD16-187	.032 x .187 (0.8 x 4.8)	.187 (4.8)	.610 (15.5)	.307 (7.8)	.197 (5.0)	.130 (3.3)	.091 (2.3)
NEW		76-MD16	.032 x .250 (0.8 x 6.4)	.250 (6.4)	.638 (16.2)	.307 (7.8)	.197 (5.0)	.130 (3.3)	.091 (2.3)
NEW	12 – 10 AWG 4–6mm <sup>2</sup>	76-MD12	.032 x .250 (0.8 x 6.4)	.250 (6.4)	.677 (17.2)	.307 (7.8)	.236 (6.0)	.177 (4.5)	.134 (3.4)