


EDSTL950/X (5.0 mm) EDSTLZ950/X (5.08 mm)

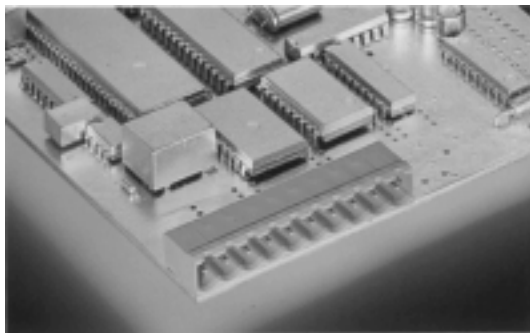

2-24 poles, Spacing 5.0 mm or 5.08 mm
insert required no. of poles **X**
How to order see page 5



Ratings:

| | | |
|-----------------------------------|-------|------------|
| Rated Voltage | 300 V | 250 V |
| Rated Current | 15 A | 12 A (T60) |
| Rating Impulse Voltage/Dirt Level | | 4 kV/3 |

Dimensions

| | |
|-------------------|------------------|
| Spacing | 5.0 mm (5.08 mm) |
| PCB Hole Diameter | 1.4 mm |

Materials

| | |
|---------------------|--------------|
| Insulating Material | PA/PBTP |
| Flammability Class | UL94 V-0 |
| Temperature Range | -30°C/+105°C |
| Contact Pin | Cu |

Color

Green

