


Part Number: AS35 0R550

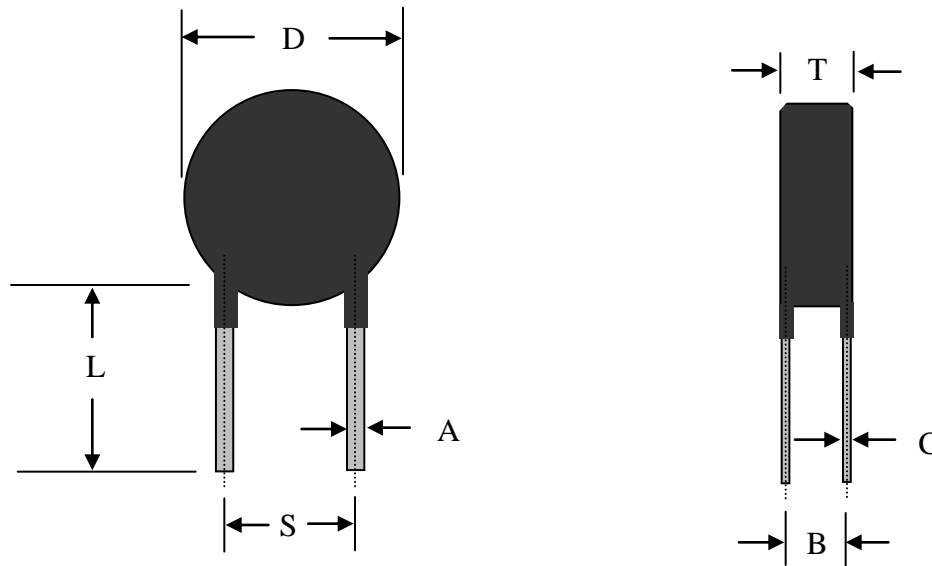

Electrical Specifications:

Resistance @ 25°C	0.5 Ω ± 25 %
Max Steady State Current Up to 65°C	50.0 A
Max recommended energy rating (Joules)	800.00 J
Actual failure point of instantaneous energy (Joules)	1400.00 J
Resistance @ 100% of Max Current	0.008 Ω
Resistance @ 50% of Max Current	0.020 Ω
Body Temperature @ 100% Current rating	210 °C
Dissipation Constant	78.20 mW/°C
Thermal Time Constant	55 seconds
Material Type	B
ROHS Compliant	Yes
MSL (moisture sensitivity level)	# 1

Mechanical Specifications:

D	36.0 mm Max
T	8.4 mm Max
S	19.0mm Nom
Straight Leads Coating run down	8.0 mm Max
L	22.0 mm Nom
A (Lead Width)	2.2 mm Nom
B	5.5 mm Nom
C (Lead Thickness)	0.8 mm Nom

Revision Date: 10/21/21