

REV. 0  
DCO 64095

COIL: @ 25°C


CUSTOMER DATA SHEET

SET	RESET
37 OHMS ±10%	37 OHMS ±10%
6.0 VDC NOMINAL VOLTAGE	6.0 VDC NOMINAL VOLTAGE
70 mADC MUST OPERATE	70 mADC MUST OPERATE

ENVIRONMENT:

VIBRATION 55 Hz 3000 Hz 30 g's  
 SHOCK 150 g's 11 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: SET/RESET 4 MS MAX.  
CONTACT BOUNCE 1.5 MS MAX.

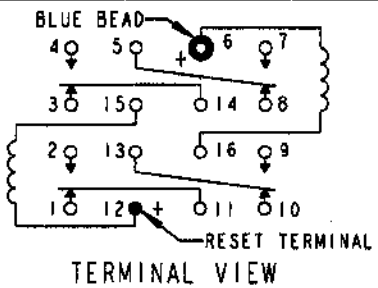

CONTACT RATING: LOW LEVEL TO  
2 AMPS 28 VDC RESISTIVE  
100,000 OPERATIONS

DR. B.D. 7/2/01 CK. TLG 7-2-01

**CII Technologies**  
 advanced control electronic solutions

CUST. CII STD.  
 CUST. NO. \_\_\_\_\_

TYPE "3SBM" RELAY

3SBM6004N2