

RXZE1M4C

Harmony, Socket, for RXM2LB/RXM4LB
relays, 7 A, screw connectors, mixed contact



Main

Range of Product	Harmony Electromechanical Relays
Product or Component Type	Socket
Contact terminal arrangement	Mixed
Product compatibility	Plug-in relay RXM 2 C/O Plug-in relay RXM 4 C/O
Device short name	RXZ
Sale per indivisible quantity	10

Complementary

[Ith] conventional free air thermal current	7 A
[Ue] rated operational voltage	250 V AC IEC
Connections - terminals	Screw clamp terminals, 1 x 0.2...1 x 1.0 mm ² AWG 24...AWG 17) flexible with cable end Screw clamp terminals, 2 x 0.2...2 x 1.0 mm ² AWG 24...AWG 17) flexible with cable end Screw clamp terminals, 1 x 0.5...1 x 1.5 mm ² AWG 20...AWG 16) solid without cable end Screw clamp terminals, 2 x 0.5...2 x 1.5 mm ² AWG 20...AWG 16) solid without cable end
Tightening torque	< 0.8 N.m M3
Fixing mode	By screw panel) Clip-on 35 mm symmetrical DIN rail)
Marking	CE
Width	1.14 in (29 mm)
Net Weight	0.12 lb(US) (0.053 kg)

Environment

[Uimp] rated impulse withstand voltage	4 kV
Overvoltage category	III
Pollution degree	3
Standards	IEC 61984
Ambient Air Temperature for Storage	-67...185 °F (-55...85 °C)
Ambient Air Temperature for Operation	-40...131 °F (-40...55 °C)
Dielectric strength	2500 V

Ordering and shipping details

Category	22153-ATV320/ATV312/ATV32 (10 THRU 30HP)
Discount Schedule	CP4B
GTIN	03389119218481
Returnability	No
Country of origin	CN

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	1.14 in (2.9 cm)
Package 1 Width	1.22 in (3.1 cm)
Package 1 Length	2.95 in (7.5 cm)
Package 1 Weight	0.11 lb(US) (0.052 kg)
Unit Type of Package 2	BB1
Number of Units in Package 2	10
Package 2 Height	2.68 in (6.8 cm)
Package 2 Width	3.15 in (8.0 cm)
Package 2 Length	5.87 in (14.9 cm)
Package 2 Weight	1.19 lb(US) (0.541 kg)
Unit Type of Package 3	S03
Number of Units in Package 3	270
Package 3 Height	11.81 in (30.0 cm)
Package 3 Width	11.81 in (30.0 cm)
Package 3 Length	15.75 in (40.0 cm)
Package 3 Weight	32.85 lb(US) (14.9 kg)


Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

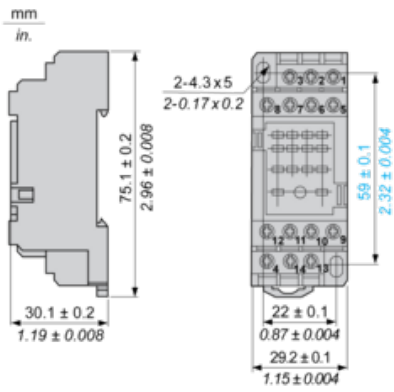

Wiring Diagram

