

TRD13D10WL04 ✓ ACTIVE

Alcoswitch | Alcoswitch TRD

TE Internal #: 1825420-1

Rocker Switches, Power, Panel Cutout Size .44 x .47 in [11.3 x 12.06 mm], Silver, Alcoswitch TRD

[View on TE.com >](#)



Relays, Contactors & Switches > Switches > Rocker Switches



Switch Type: **Power**

Indicator/Imprint Legend: **None**

Panel Cutout Size: **11.3 x 12.06 mm [.44 x .47 in]**

Switch Contact Plating Material: **Silver**

Lamp: **Without**

Features

Product Type Features

Switch Connection Type	Wire Lugs
Switch Type	Power
Lamp	Without
Actuator Type	Top
Actuator Style	Rocker

Configuration Features

Indicator/Imprint Legend	None
Panel Cutout Size	11.3 x 12.06 mm [.44 x .47 in]
Configuration (Pole-Throw)	Single Pole - Double Throw
Operating Function	On None On

Electrical Characteristics

Operating Voltage Range	28 VDC
-------------------------	--------

Body Features

Product Orientation	Vertical
---------------------	----------



Actuator Color Black

Contact Features

Switch Contact Plating Material Silver

Contact Current Rating 3 A

Housing Features

Process Sealed No

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU Compliant with Exemptions

EU ELV Directive 2000/53/EC Compliant

China RoHS 2 Directive MIIT Order No 32, 2016 Restricted Materials Above Threshold

EU REACH Regulation (EC) No. 1907/2006
 Current ECHA Candidate List: JUNE 2023 (235)
 Candidate List Declared Against: JUNE 2023 (235)
 SVHC > Threshold:
 Pb (4% in Component)

Article Safe Usage Statements:
 Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

Halogen Content Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability Hand solderable with lead free solder

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulations, TE's information on SVHC in articles for this part number is still based on the European Chemical Agency (ECHA) 'Guidance on requirements for substances in articles' (Version: 2, April 2011), applying the 0.1% weight on weight concentration threshold at the finished product level. TE is aware of the European Court of Justice ruling of September 10th, 2015 also known as O5A (Once An Article Always An Article) stating that, in case of 'complex object', the threshold for a SVHC must be applied to both the product as a whole and simultaneously to each of the articles forming part of its composition. TE has evaluated this ruling based on the new ECHA "Guidance on requirements for substances in articles" (June 2017, version 4.0) and will be updating its statements accordingly.

Compatible Parts



TE Part # 4-1437595-1
TRD11D10WL=SPDT ROCKER BLACK



TE Part # 5-1437595-6
TRD11G10WL=ROCKER SW SPDT (ON)



TE Part # 5-1437595-9
TRD11H10WL=ROCKER GOLD ON OFF




TE Part # 4-1437595-2
TRD11D10WLLR5=SP ROCKER LIGHTE



TE Part # 1825426-1
TRD13D10WLLR204 rocker switch

Also in the Series | Alcoswitch TRD

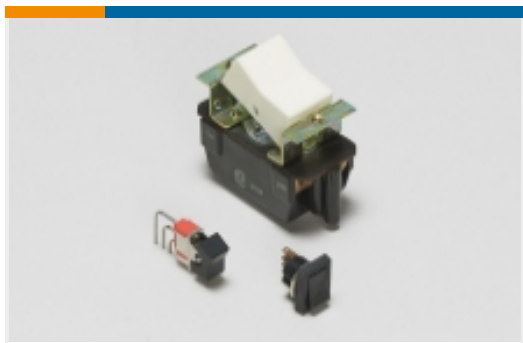

Rocker Switches(33)

Customers Also Bought



TE Part #33695
TERMINAL,BUDG R 26-22 2



TE Part #535541-1
03 MODIV VRT SR CE 100/115



TE Part #9-1423364-6
W57-XB1A7A10-5=CKTBKR,THERM, PB,SCW/QC




TE Part #FC2231-0000-0010-L
MID RANGE COMPRESSION SENSOR



TE Part #6609929-5
PE0SXDXHB=C2219



TE Part #LM31-00000F-001PG
1PSIG LIQUID LEVEL PRESSURE TRANSDUCER

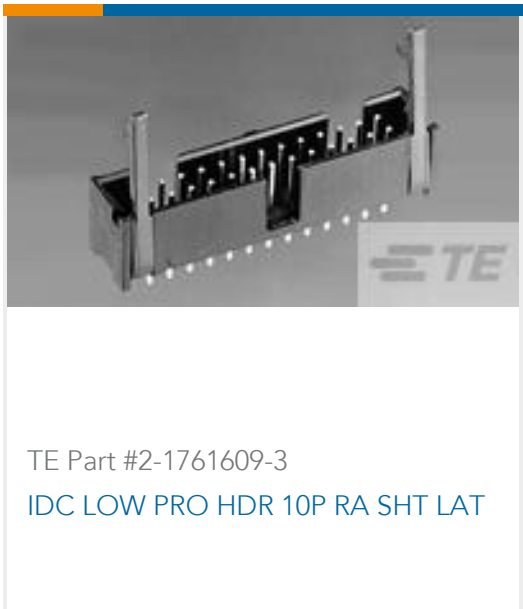

TE Part #2-1761609-3
IDC LOW PRO HDR 10P RA SHT LAT



TE Part #5555167-1
MJ,LPF,R/A,8P/8C,KEYED,BULK P



Documents

Product Drawings

[TRD13D10WL04 rocker switch](#)

English

CAD Files

Customer View Model

[ENG_CVM_CVM_1825420-1_A.2d_dxf.zip](#)

English

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_1825420-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1825420-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[SWITCHES_CORE_PROGRAM_CATALOG](#)

English