

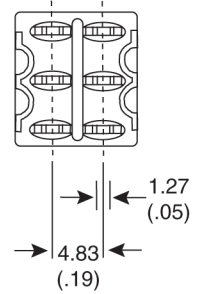
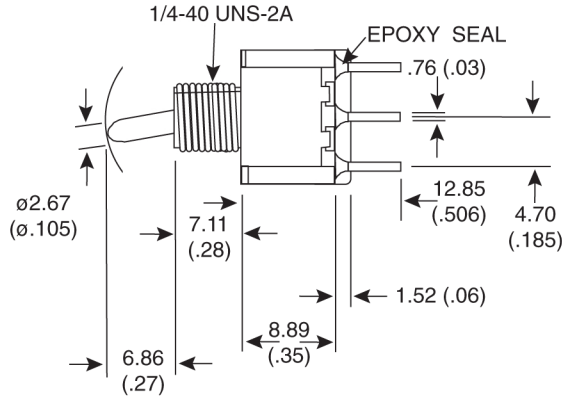


**DIMENSIONS: mm (in.)**

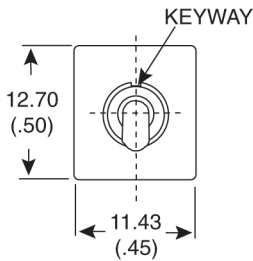


POS.1	POS.2
ON	ON
2-3,5-6	2-1,5-4

SWITCH FUNCTION

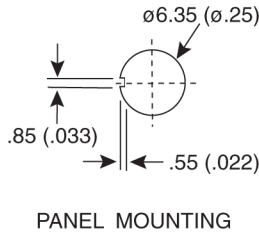

PANEL MOUNTING

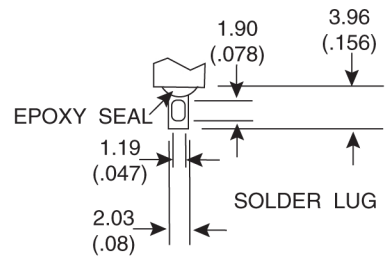

**Electrical Specifications:**

- Electrical Life: 40,000 make-and-break cycles at full load
- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS@ sea level
- Rating: 2A / 250 VAC; 5A / 120 VAC or 28 VDC

**Mechanical Specifications:**

- Operating Temperature: -30°C to +85°C

**Note:**

- RoHS compliant by exemption

**Materials:**

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Terminal/Contact: Silver or Gold plated

