



Electrical specifications

Center Frequency: 1000 MHz
Bandwidth: 20 MHz typ
VSWR: 1.5 : 1 max
Input / Output Impedance: 50 Ohms
Passband: 990-1010 MHz
Passband Insertion Loss: 3.2 dB max
Rejection: 65 dBc min 800 MHz
Rejection 2: 65 dBc min 1200 MHz
Power Handling: 20 dBm

Mechanical


Mounting Method: SMT
Dimensions: 13mm x 12mm x 5.5

Environmental

Operating Temperature: -40°C to 85°C
Storage Temperature: -50°C to +90°C

This product is RoHs compliant.

Outline Drawing:

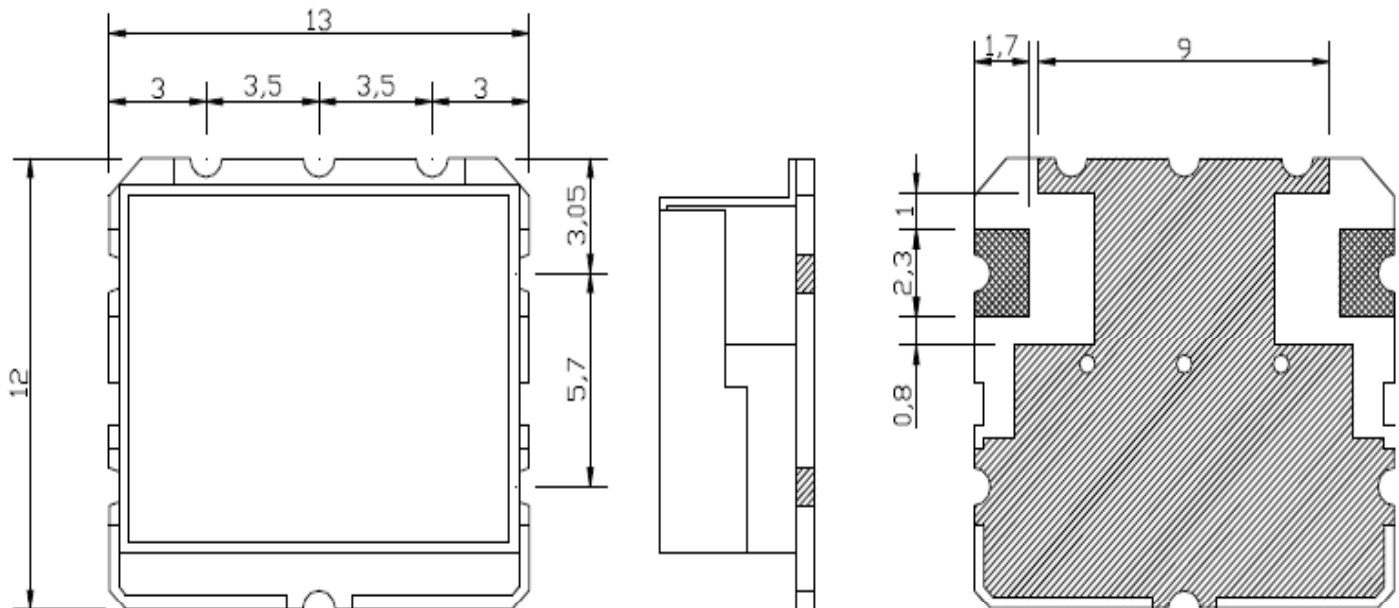



Response Plot:

