



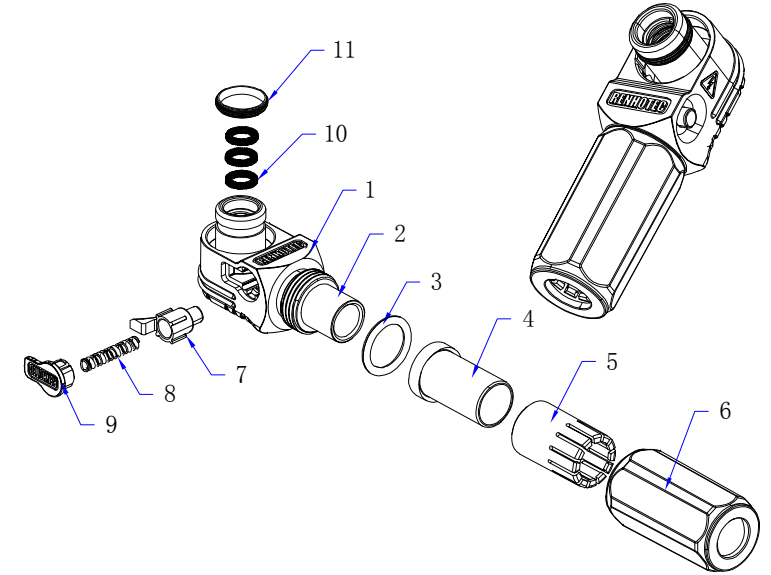

版本	描述	绘制	日期	核准
A	首次发行	FULIU	2023/03/01	

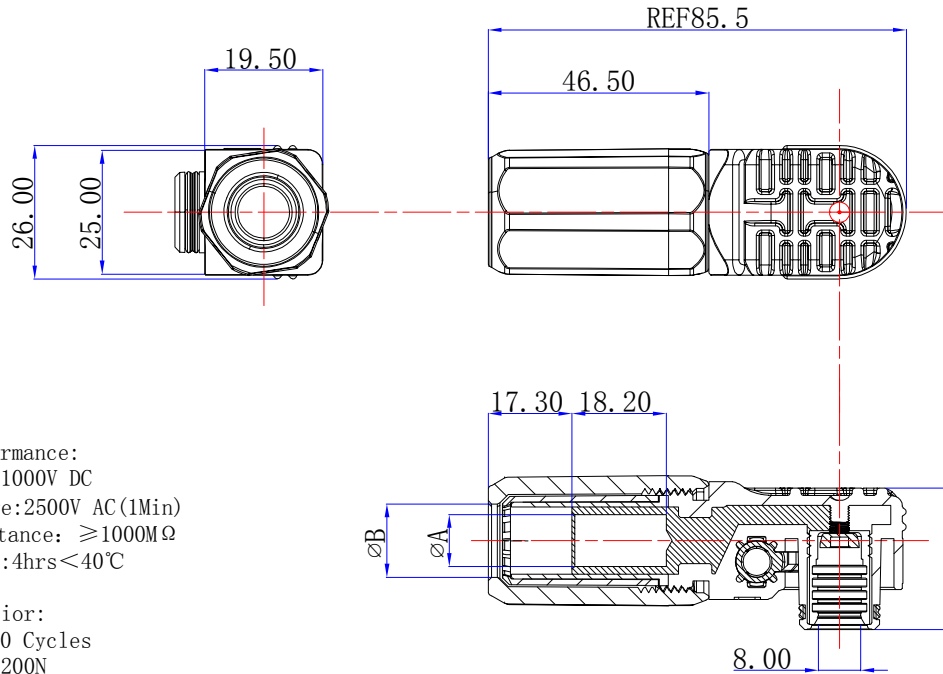

Electrical performance:
 Voltage Rating: 1000V DC
 Withstand voltage: 2500V AC(1Min)
 insulation resistance: $\geq 1000M\Omega$
 Temperature Rise: 4hrs < 40°C

Mechanical behavior:
 Durability: >2000 Cycles
 M&F Holding F: >200N
 IP Level: IP67
 Temperature Rating: -40 °C ~ +105 °C
 Flammability: UL94V-0
 <The product has passed CE certification>



P/N	Colour	Rated current	wire gage	A	B
DOSIN-888-0020-01	Black	120A	25mm ²	7.80	10.20
DOSIN-888-0020-02	Orange				
DOSIN-888-0020-03	Red				
DOSIN-888-0020-04	Black	150A	35mm ²	9.00	11.70
DOSIN-888-0020-05	Orange				
DOSIN-888-0020-06	Red	200A	50mm ²	10.70	13.80
DOSIN-888-0020-07	Black				
DOSIN-888-0020-08	Orange				
DOSIN-888-0020-09	Red				

NO	Description	Material	Finish	Qty
11	Insertion Sealing	Silicone		1
10	Type O contact ring	C17200	Ag	3
9	Button Name	PA66		1
8	Spring	Stainless Steel		1
7	Plastic Button	PA66		1
6	Tail Cover	PA66		1
5	Cable Clamp	PA66		1
4	Rubber Sealing	Silicone		1
3	O-Ring	Silicone		1
2	Socket	T2	Ag	1
1	Receptacle Shell	PA66		1
NO	Description	Material	Finish	Qty

公差	X.	±0.50	DOSIN INDUSTRIAL (HK) CO., LTD 东莞市德索五金电子有限公司 Dongguan Dosin Hardware Electronics Co., Ltd.	Web: http://www.dosinconn.com dosin2005@dosin-china.com Tel: (0086) 769-81153906 Fax: (0086) 769-81875836
	X.X	±0.20		
视图	X.XX	±0.10	品名: 8mm 90 angled plug (black/orange/red)	
	Angular	±5°		
单位		MM	料号: DOSIN-888-0020-XX	版本: A
比例		1 : 1	客户料号: /	页码: 1 OF 1