

6

5

4

3



2

1

APPROVED: _____

DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-	7375	RELEASED	12/15/06	

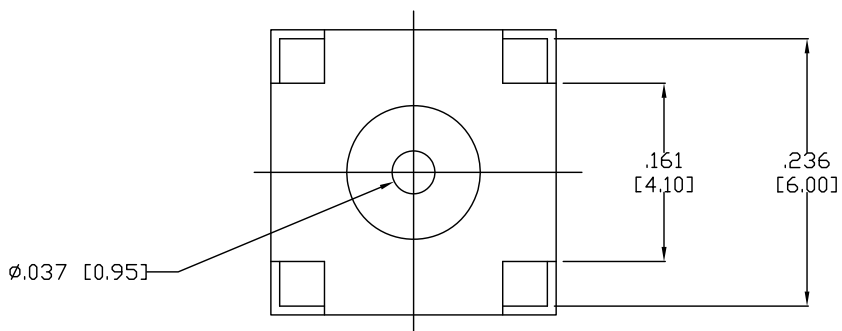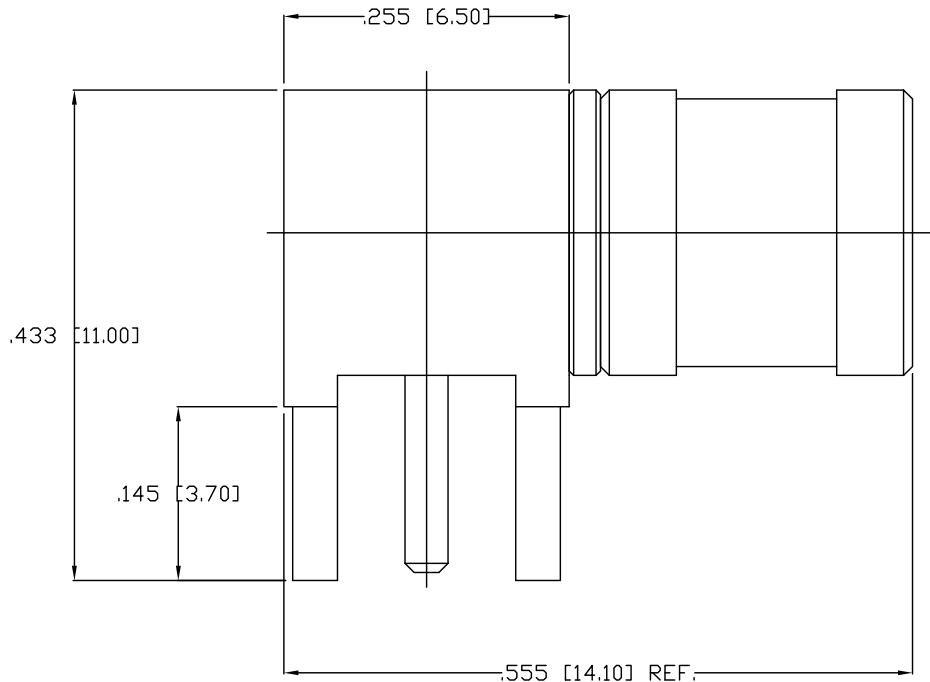

3	INSULATOR	TEFLON	1	WHITE
2	PIN	BRASS	1	GOLD
1	BODY	BRASS	1	GOLD
ITEM	DESCRIPTION	MAT'L	QTY	PLATING

SPECIFICATIONS:

Electrical:
 Nominal Impedance: 50 ohms
 Frequency range: 0-4 GHz
 Maximum peak voltage: 500V
 Insulation resistance: 5000 Mohm min @ 500 VDC
 Dielectric withstanding voltage: 1500 VAC rms
 Environmental:
 Lead free, RoHS compliant.
 Recommended soldering temp: 235°C for 5 sec.



UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE MM [INCHES] TOLERANCES: EXCEPT AS NOTED		
INCHES HOLES		
.X ± .10	Ø.X ± .10	
.XX ± .020	Ø.XX ± .015	
.XXX ± .015	Ø.XXX ± .010	
APPROVALS		DATE
DRAWN	BW	12/15/06
CHECKED		
APPROVED		

ADAM TECH

909 Rahway Avenue, Union, NJ 07083
 Phone: 908-687-5000 Fax: 908-687-0214

TITLE RIGHT ANGLE SMB PLUG PCB MOUNT 50 OHM		
SIZE X	PART NO. RF3-04-T-00-50-G	REV. -
REF:	SCALE: NTS	SHEET 1 OF 1

6

5

4

3

2

1