

Type BLC-112

Fuse Block

12 Pole – Regular Auto Blade




www.optifuse.com (619) 593-5050

Specifications:

- Max Current Rating:** 25A per Circuit - 150A Max Input
- Max Voltage:** 32VDC
- Fuse Type:** Regular Auto Blade (APR series)
- Body Material:** Polycarbonate (UL94V-2)
- Terminals:** 12 ea Copper, Tin plated 0.250" Quick Connect Terminals,
1 ea #10-32 stud terminal with hex nut, flat washer and lockwasher supplied.
- Mounting:** 4 mounting holes for #10-32 screws (not supplied)
- Cover available:** BLC-112-C

Mechanical Dimensions: Inches [mm]

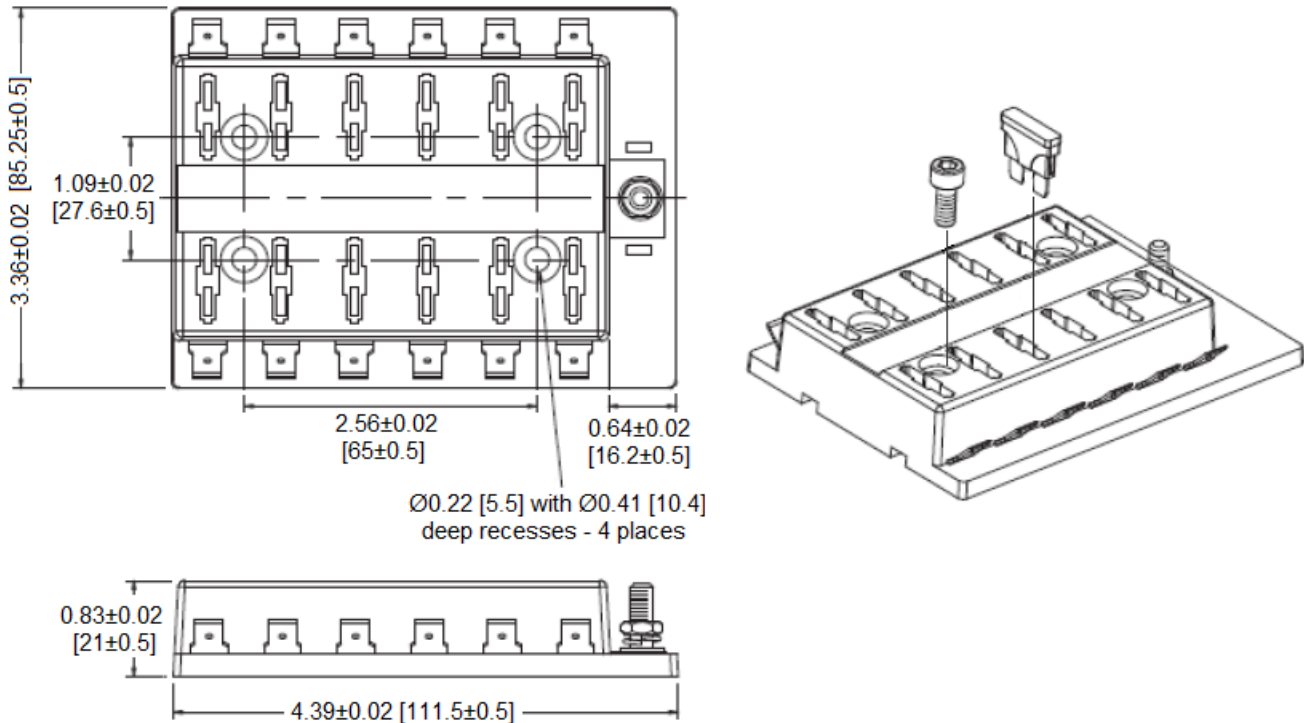

	<p>Warning:</p> <p>-Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.</p>
	<p>-Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.</p>