

# Type BLS-310

## Fuse Block

### 10 Pole-Low Profile Mini Auto Blade




www.optifuse.com (619) 593-5050

#### Specifications:

- Max Current Rating:** 30A per Circuit - 100A Max Input
- Fuse Type:** Low Profile Miniature Auto Blade – APS, ANS series
- Base:** PBT (UL-Flame 94V-0), Black
- Cover:** PC (UL-Flame 94V-2), Transparent
- Terminals:** Tin Plated Brass - 0.250" Quick Connect Terminals
- Temperature Rating:** -20° C ~ +85° C

#### Mechanical Dimensions: Inches [mm]

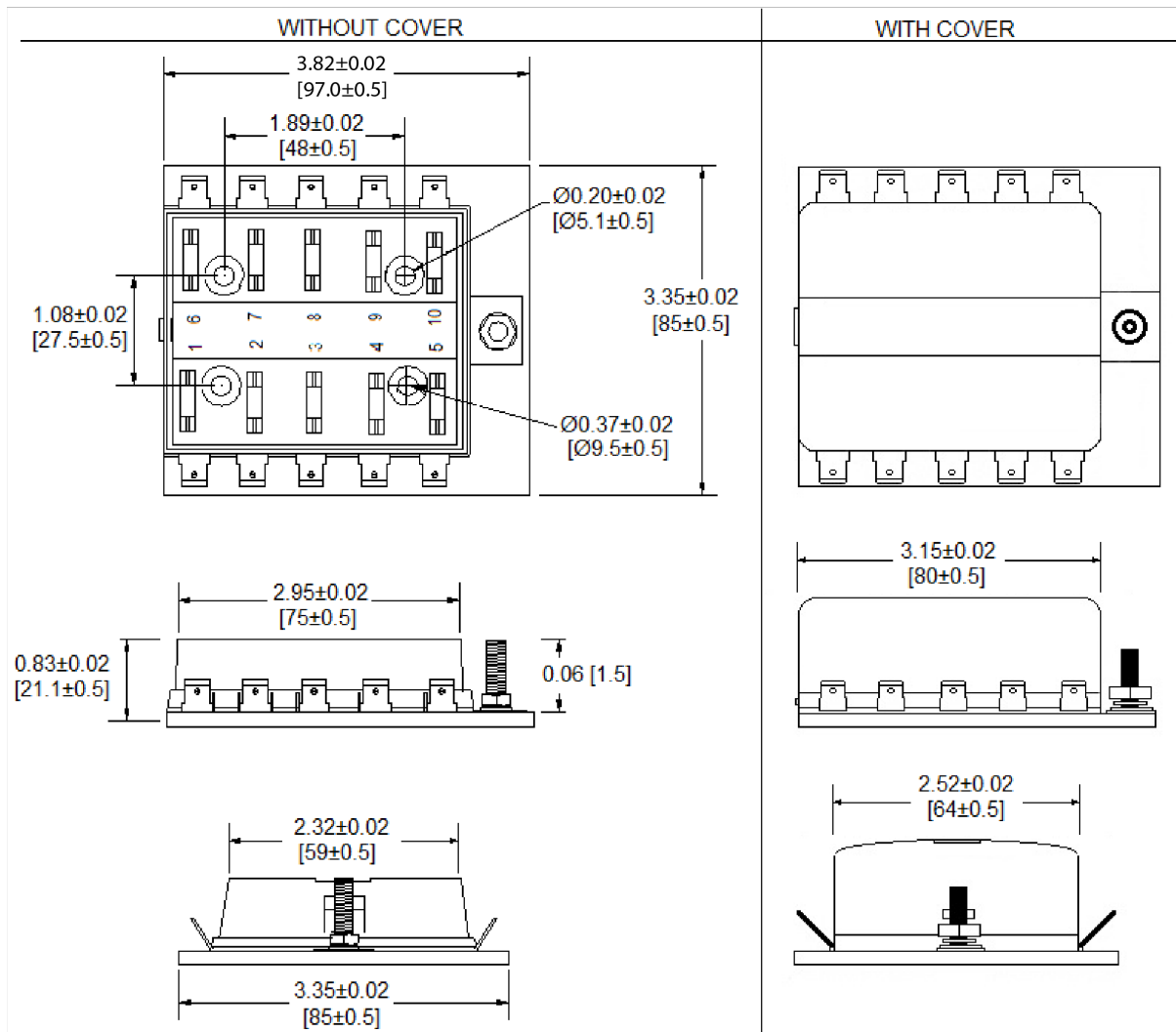

#### Warning:



-Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.

-Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.