

Type LPA-24
In-Line Fuse Holder
1/4" x 1 1/4" (6.3 x 32mm) Fuses



www.optifuse.com (619) 593-5050

Ratings:

Fuse Type: 1/4" x 1 1/4" (6.3 x 32mm)
Electrical Rating: 20A (#14AWG), 30A (#12AWG)
 250VAC, 32VDC
Body and Cap: Phenolic (UL flame: 94V-1)
Standard Wire Sizes: #12 ~ #14 AWG
Standard Wire Colors: Red
Standard Body colors: Black
Standard Wire Length: 7.87 inches [200mm] loop


Part number


LPA-24B-##R
 where ## = Wire gauge

Agency Standards and Listings:



Mechanical Dimensions: Inches [mm]

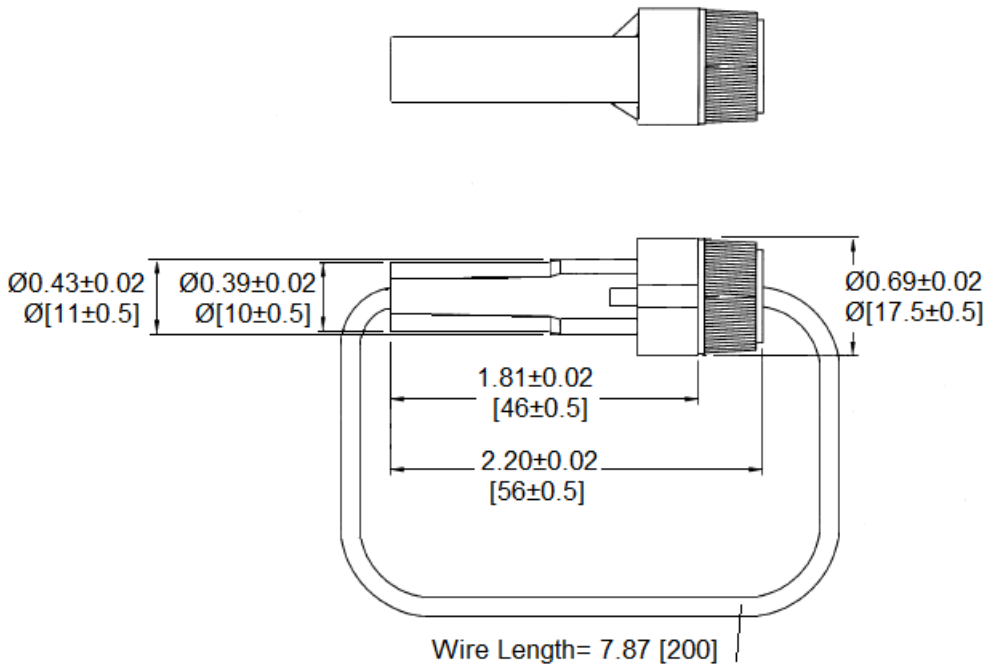

<p>Warning:</p> 	<ul style="list-style-type: none"> -Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame. -Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance. -Not designed for prolonged liquid exposure or submersible applications.
--	---