

# Type BLC-112-G

## Fuse Block

### 12 Pole – Regular Auto Blade Type

### With 12-Position Grounding Block






www.optifuse.com (619) 593-5050

**Specifications:**

- Max Current Rating:** 25A per Circuit - 150A Max Input
- Max Voltage:** 32VDC
- Fuse Type:** Regular Auto Blade (APR series),  
Regular Automotive Circuit Breakers (ACBP4-PL and MRCBP4-PL series)
- Body Material:** Polycarbonate (UL94V-2)
- Load-side Connection:** 0.250" Quick Connect Terminals - Copper, Tin plated 0.250"
- Line-side Connection:** #10-32 stud terminal with hex nut, flat washer, lockwasher (hardware provided)
- Mounting:** 5.5mm diameter mounting holes for #10 screws (not provided)
- Optional Cover available**

**Mechanical Dimensions: Inches [mm]**

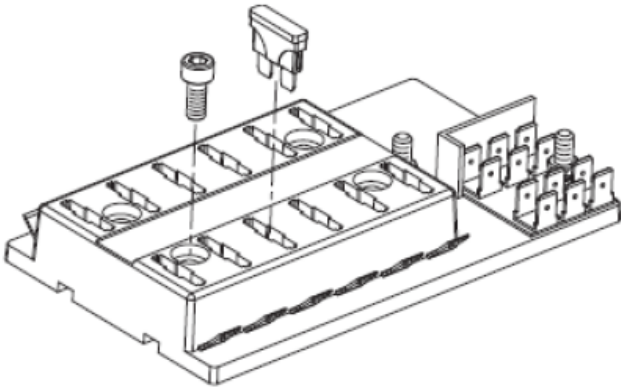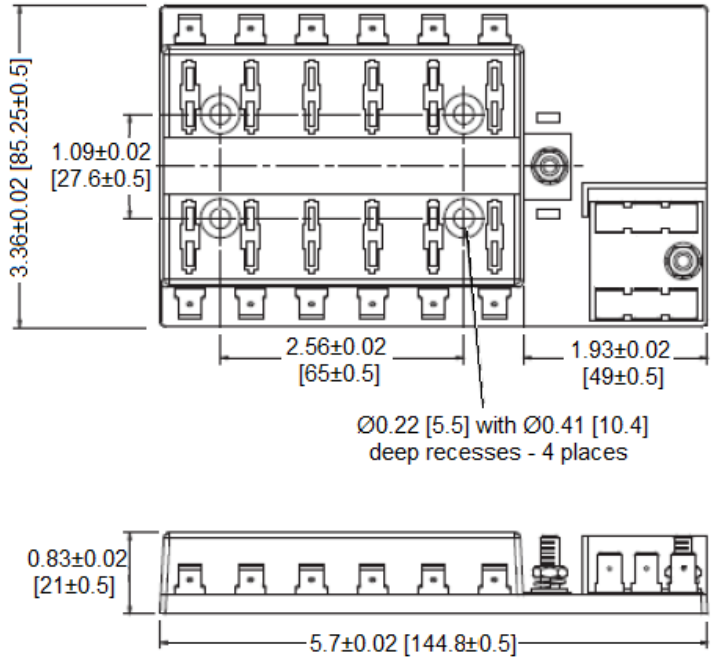

<p><b>Warning:</b></p> 	<ul style="list-style-type: none"> <li>-Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.</li> <li>-Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.</li> </ul>
--	---