



- Vertical Mount
- UU Core Design
- Operating Temperature Range: -55°C to +105°C




| Electrical Specifications | | | | |
|--|----------------------------|--|---------------------|------------|
| Inductance (L) @ 1KHz, 0.25V N1 = N2 | DCR (mΩ) Max N1 = N2 | I _{rms} @ 1KHz, 0.25V (A) Max | HiPot 5mA / 2Sec | |
| | | | Wdg - Wdg | Wdg - Core |
| 10mH Min | 220 | 1.5 | 3750Vac | 2000Vac |


All specifications subject to change without notice.

MECHANICAL

Dimensions: $\frac{\text{inch}}{\text{mm}}$

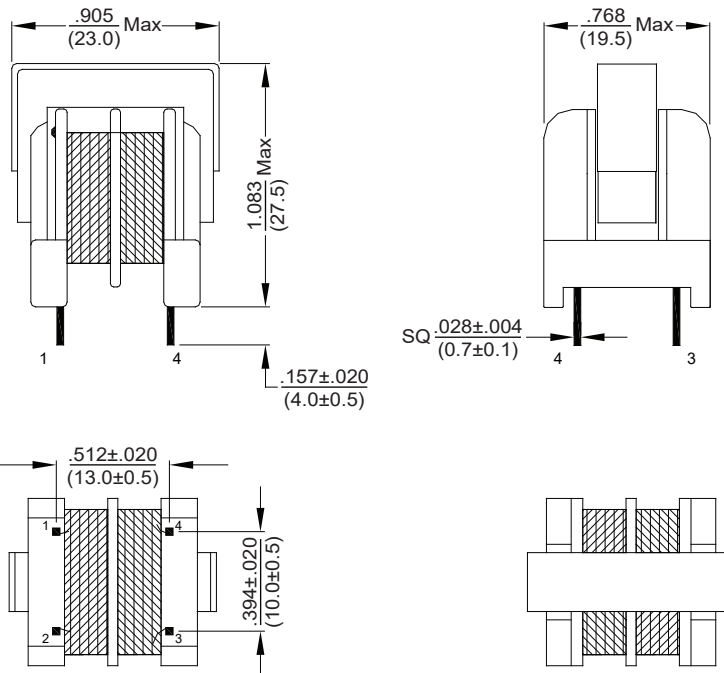

SCHEMATIC

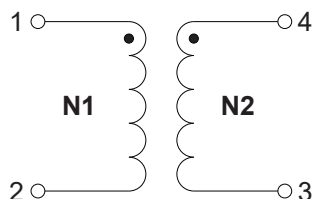

WINDING CONSTRUCTION

