



Wire-end ferrules, Max. wire cross-section: 10 mm<sup>2</sup>, Length: 22 mm, Length of copper pipe: 12 mm, Colour: Ivory

### Business data

Article number	3026.0
Article name	H 10,0/22-D SR IV
GTIN (EAN)	4044211184049
Packaging unit	100
Quantity unit	PC
Weight per piece (not including packaging)	0.05 g
Weight per piece (including packaging)	0.06 g
Unit of weight	G
Customs number	85369010
Country of origin	DE
Product description	Ferrules
Colour	Ivory

---

### Technical data

---

#### Dimensions

Length	22 mm
Length of copper pipe	12 mm
Diameter of copper pipe	4.5 mm
Diameter plastic collar	7.6 mm
Wall thickness of copper pipe	0.2 mm
Wall thickness of plastic collar	0.5 mm

#### Connection data

Wire cross-section, max.	10 mm <sup>2</sup>
Wire cross-section AWG, max.	8
Stripping length	15 mm

#### Materials

Copper pipe	Copper alloy
Surface	Galvanically tin-plated, shiny
Plastic collar	Polypropylene homopolymer
Working temperature, min.	-5 °C
Working temperature, max.	105 °C

#### Further technical data

Insulation available	✓
----------------------	---

#### Environmental Product Compliance

REACH Conform	yes
REACH Reference date	2023-06-14
REACH Candidate Substance Note	No
RoHS Conform	yes

### Approvals

---

#### Standards and regulations

---

DIN 46228-4:1990	yes
------------------	-----

---


---

### Media

---

### Accessories

#### ##INVERSE##CONTA-CONNECT

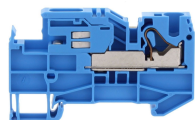


Neutral-disconnect terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 8.1 mm, Colour: Blue

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3274.5</u>	FNT 6-10 BU	4044211138981	100 ST




PE installation terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 8.1 mm, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3217.2</u>	FSLI 6-10/3A GNYE	4044211199944	50 ST

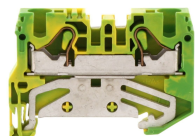


PE installation terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 8.1 mm, Colour: Green-yellow

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3280.2</u>	FSLI 6-10 GNYE	4044211139100	100 ST

 

Feed-through installation terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 8.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3216.2</u>	FRKI 6-10/3A BG	4044211199913	50

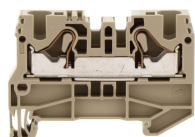

Feed-through installation terminal, Push-in connection, Mounting type: Mounting rail TS 35/7.5, Rated cross-section: 10 mm<sup>2</sup>, Width: 8.1 mm, Colour: Beige

Article number	Article name	GTIN (EAN)	Packaging unit
<u>3277.2</u>	FRKI 6-10 BG	4044211139032	100