
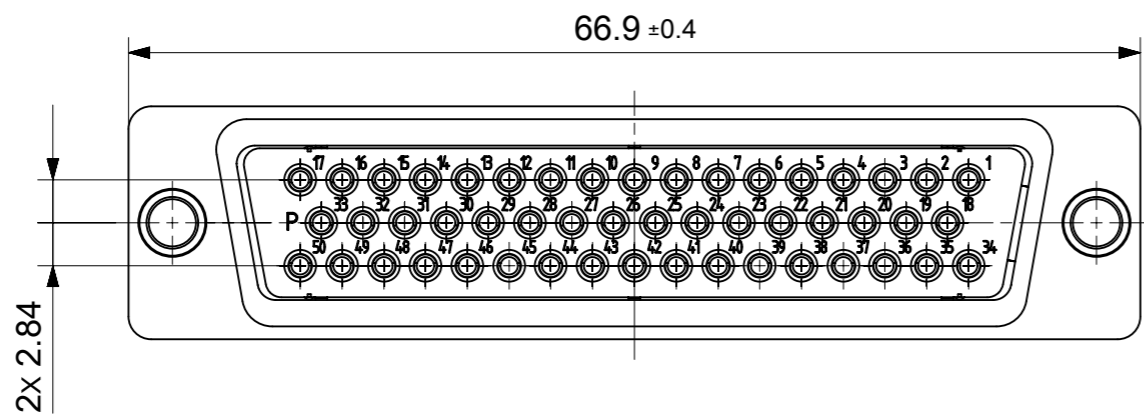
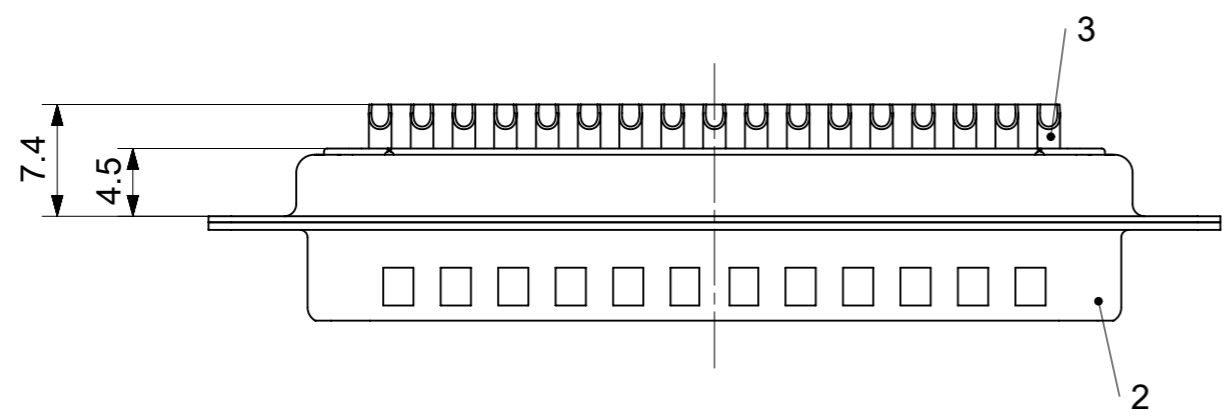
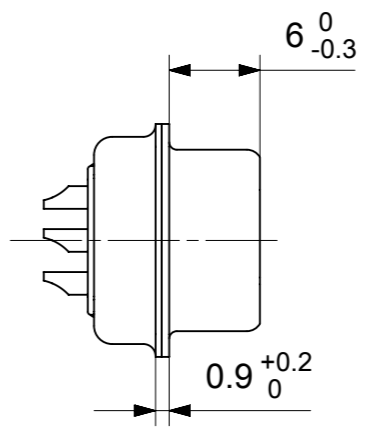


RoHS compliant  
by exemption

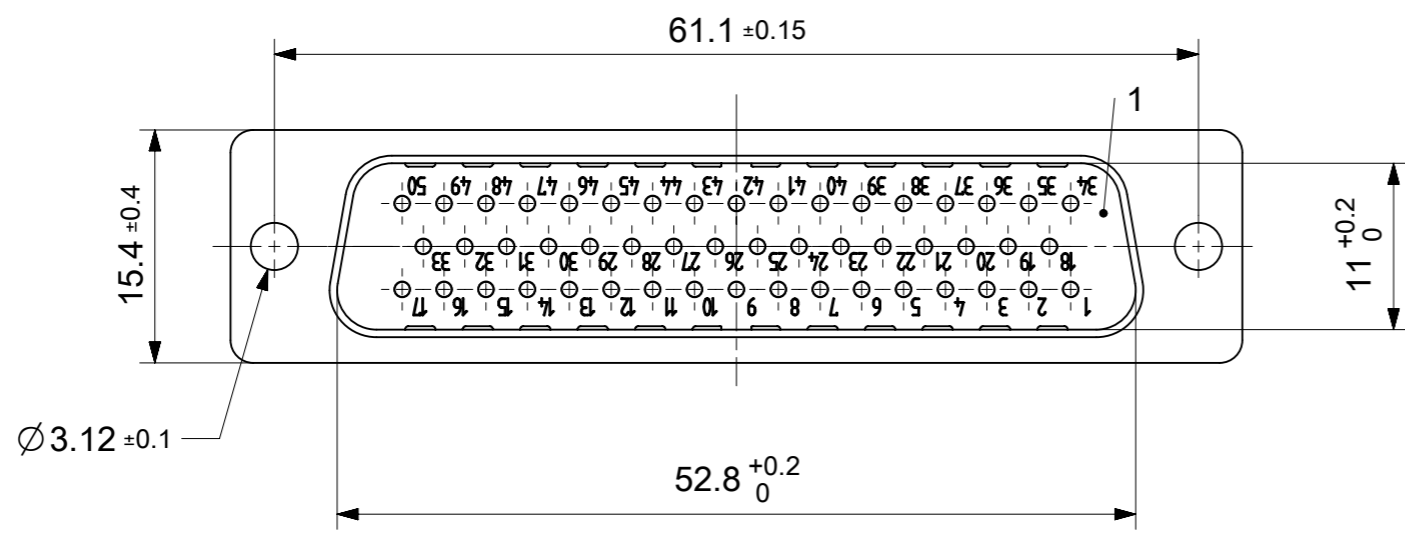

FCT Part number:  
F50P0G1A

Material Number
1731090313

3	50	Signal contact	P0 / Brass	AuroPur / AWG 20
2	1	Shell	Steel	tin plated
1	1	Insulator	PBT (-55°C to +125°C) acc. UL94V-0	white
No.	Pc.	Part	Type Description/Material	Surface plating/ Color/Class

MEASUREMENTS WITHOUT TOLERANCE ACC TO ISO 2768-m			REPLACEMENT FOR DOCUMENT NUMBER: F50P0G1A		
FUNCTIONAL SYMBOLS					
$\nabla_A = 0$	mm	2:1	CURRENT REV DESC:		
GENERAL TOLERANCES (UNLESS SPECIFIED)			EC NO: 712973		
$\nabla_E = 0$	ANGULAR TOL ± °		DRWN: SKANDB 2022/02/01		
$\nabla_F = 0$	4 PLACES ±		CHK'D: MTEUBEL 2022/07/12		
DIVISIONAL SYMBOLS			APPR: MTEUBEL 2022/07/12		
3 PLACES ±	INITIAL REVISION:		DOCUMENT NUMBER		
2 PLACES ±	DRWN: SKANDB 2022/02/01		1731090313		
1 PLACE ±	APPR: MTEUBEL 2022/07/12		DOC TYPE DOC PART REVISION		
0 PLACES ±	DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		PSD 000 A		
FIRST ANGLE PROJECTION		DRAWING	SERIES	MATERIAL NUMBER	CUSTOMER
A3-SIZE		173109	SEE TABLE	GENERAL MARKET	SHEET NUMBER
					1 OF 1