
 


PAGE 1/2	ISSUE 19-01-17A	SERIES SPLITTER	PART NUMBER R434514003
----------	-----------------	---------------------------	-------------------------------

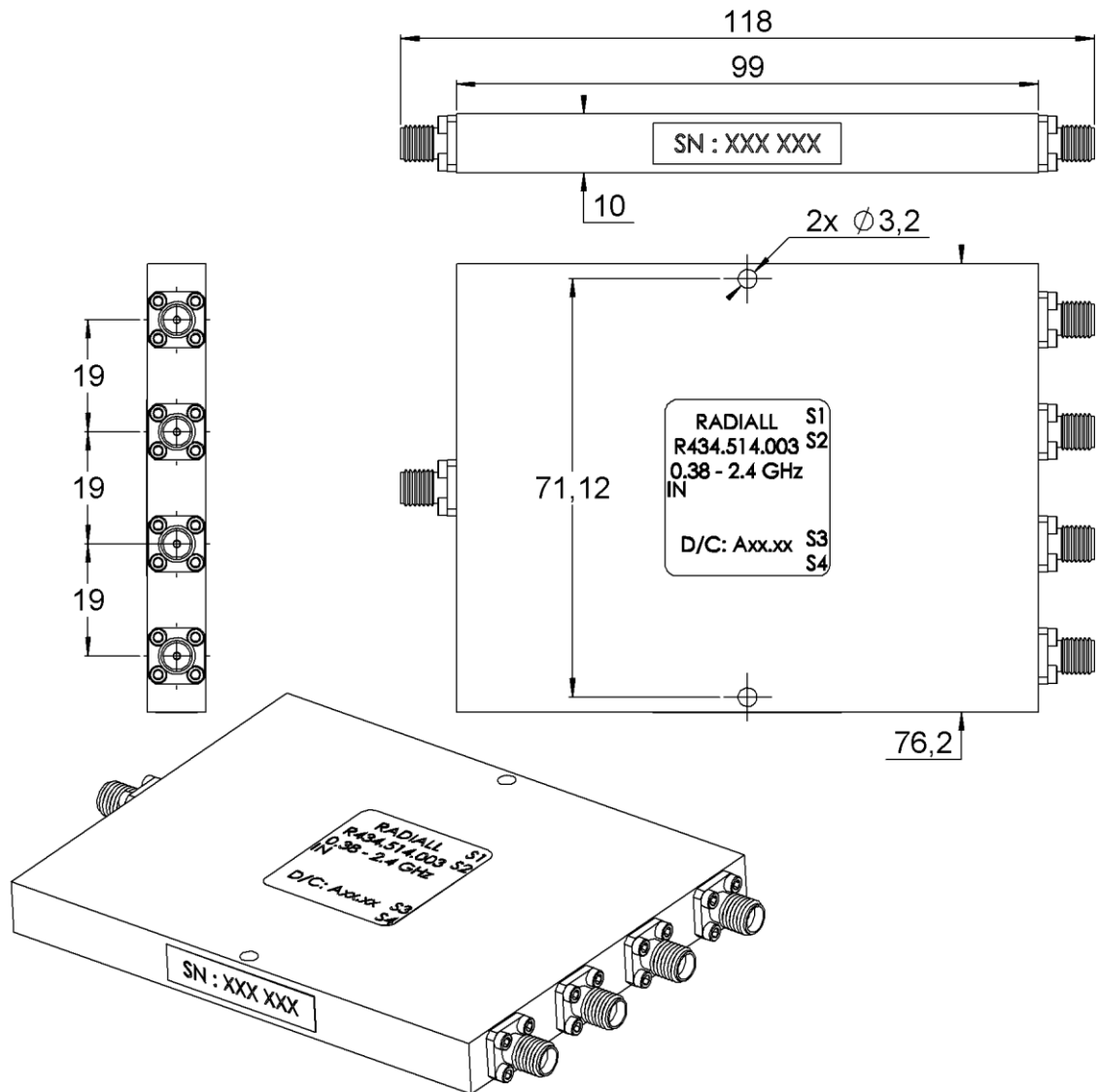

All dimensions are in mm.

Weight **207,3210** g
Specification



PAGE 2/2	ISSUE 19-01-17A	SERIES SPLITTER	PART NUMBER R434514003
----------	------------------------	---------------------------	-------------------------------

ELECTICAL CHARACTERISTICS

Frequency range :	0.38 – 2.4 GHz
Number of ways	4
Phase	0°
VSWR	
Input	1.5
Output	1.5
Impedance	50 Ohms
Insertion loss	1.3 dB max
Isolation	20 dB mini
Amplitude balance	± 0.5 dB
Phase Balance	± 6°
Average Power	
VSWR load < 1.2	30W
VSWR load : inf	1W

MECHANICAL CHARACTERISTICS

Connectors :	
Input	SMA female
Output	SMA female
Body	Aluminium
Finish	Blue Paint

ENVIRONMENTAL CHARACTERISTICS

Operating temperature	-40 / +85 °C
Storage temperature	-55 / +125 °C