
 


PAGE 1/2	ISSUE 26-08-16A	SERIES <b>SPLITTER</b>	PART NUMBER <b>R434112002</b>
----------	-----------------	---------------------------	-------------------------------

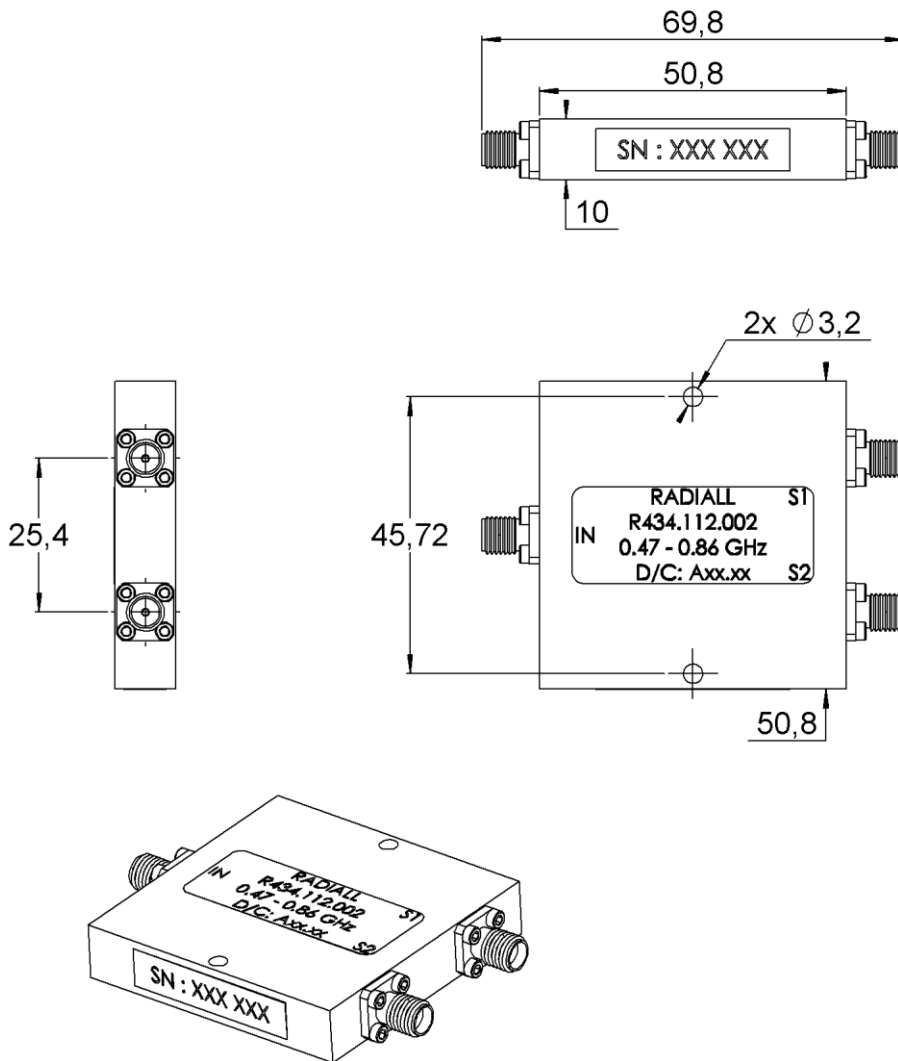

All dimensions are in mm.

Weight **73,5760** g  
Specification



PAGE 2/2	ISSUE <b>26-08-16A</b>	SERIES <b>SPLITTER</b>	PART NUMBER <b>R434112002</b>
----------	------------------------	---------------------------	-------------------------------

### ELECTICAL CHARACTERISTICS

Frequency range :	0.47 – 0.86 GHz
Number of ways	2
Phase	0°
VSWR	
Input	1.3
Output	1.3
Impedance	50 Ohms
Insertion loss	0.3 dB max
Isolation	23 dB mini
Amplitude balance	± 0.3 dB
Phase Balance	± 2°
Average Power	
VSWR load < 1.2	30W
VSWR load : inf	1W

### MECHANICAL CHARACTERISTICS

Connectors :	
Input	SMA female
Output	SMA female
Body	Aluminium
Finish	Blue Paint

### ENVIRONMENTAL CHARACTERISTICS

Operating temperature	-40 / +85 °C
Storage temperature	-55 / +125 °C