



Electrical Specifications

Cutoff Frequency (Fc): 470 MHz
Passband: 470-10000 MHz min.
Passband Insertion Loss: 1.0dB Max.
Return Loss: 12dB Min.
Rejection: 30 dB Min. @ 250 MHz
Impedance: 50 Ohms In/Out


Mechanical

Connector Type: SMA(F)
Dimensions: 1.5" x 1.5" x 0.75"

Environmental

Operating Temperature: -25°C to +70°C
Storage Temperature: -40°C to +90°C
Shock: 10 G. 11ms
Vibration: 10 G. 5 to 200Hz

Outline Drawing:

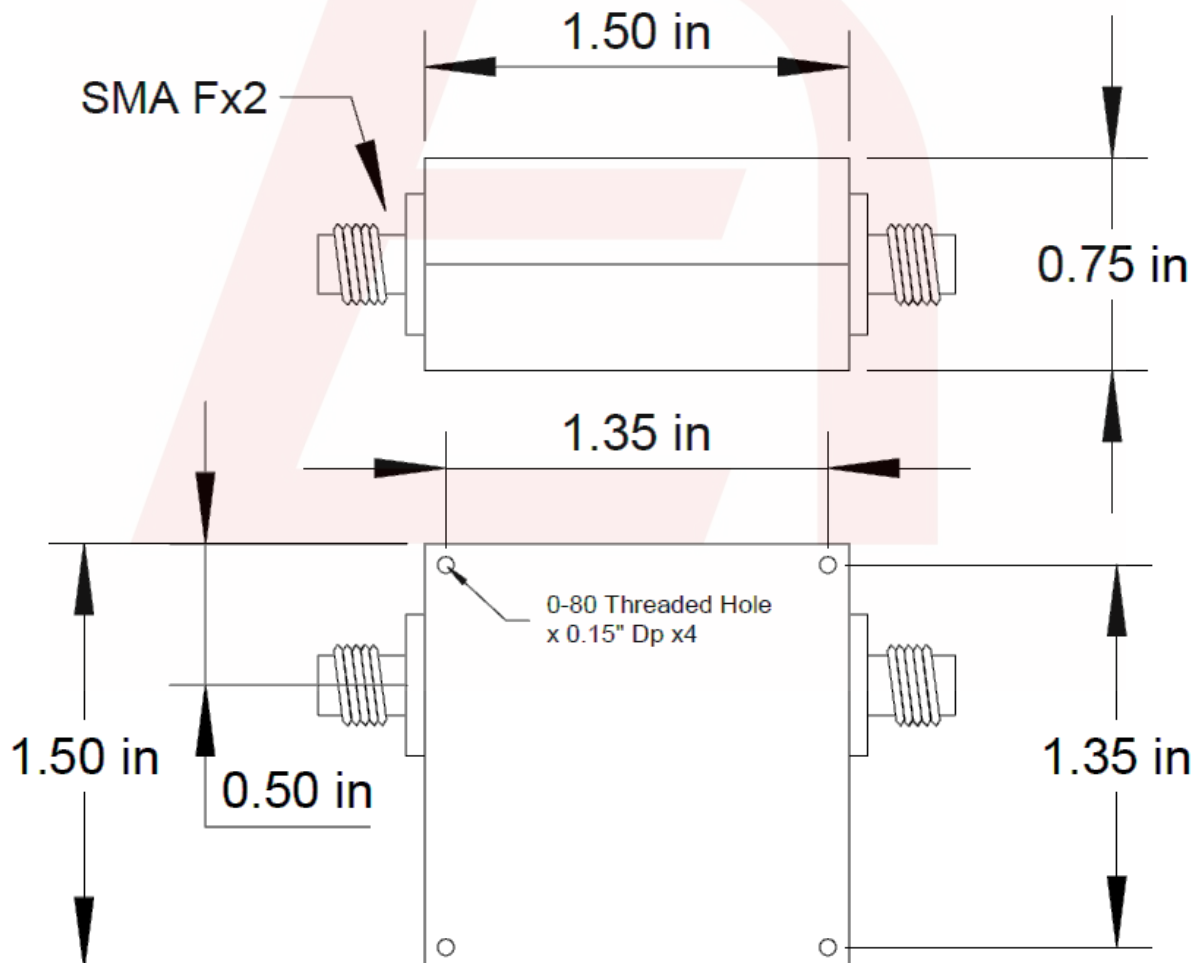

DS-H9109-10022020-Rev0