



Electrical Specifications

Pass Band: 400-800 MHz
Insertion Loss in Pass Band: 1.0 dB Max
Rejection: >80 dB @ DC-250 MHz
Power Handling: 10 W Max


Mechanical

Connector Type: SMA (F)
Dimensions: 1.5 x 0.75 x 0.5 Inches

Environmental


Operating Temperature: -40 to +70° C
Storage Temperature: -50 to +85° C
Shock: 20 G. 11 ms
Vibration: 20 G. 5 to 200 MHz

Outline Drawing:

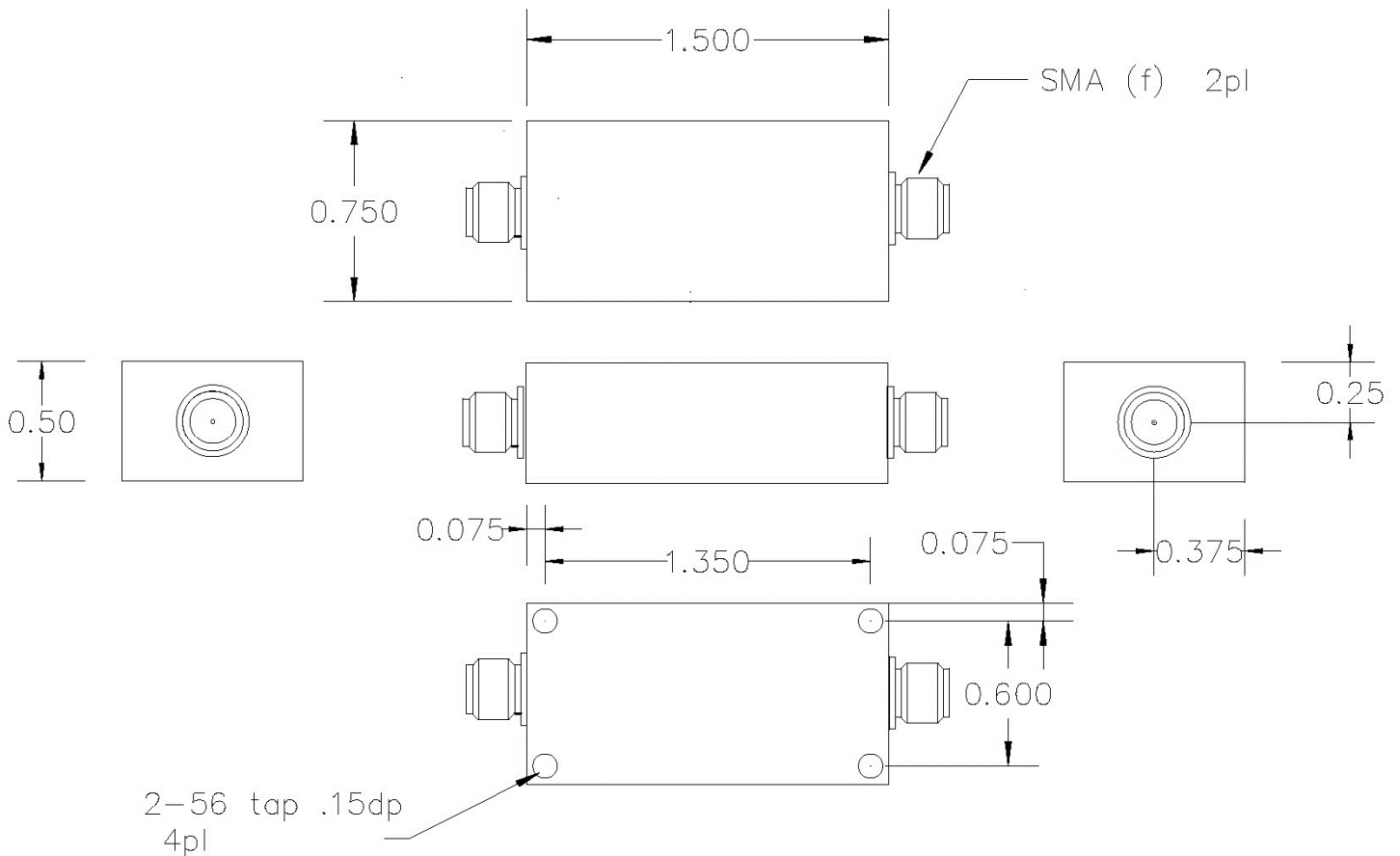



Outline Drawing:

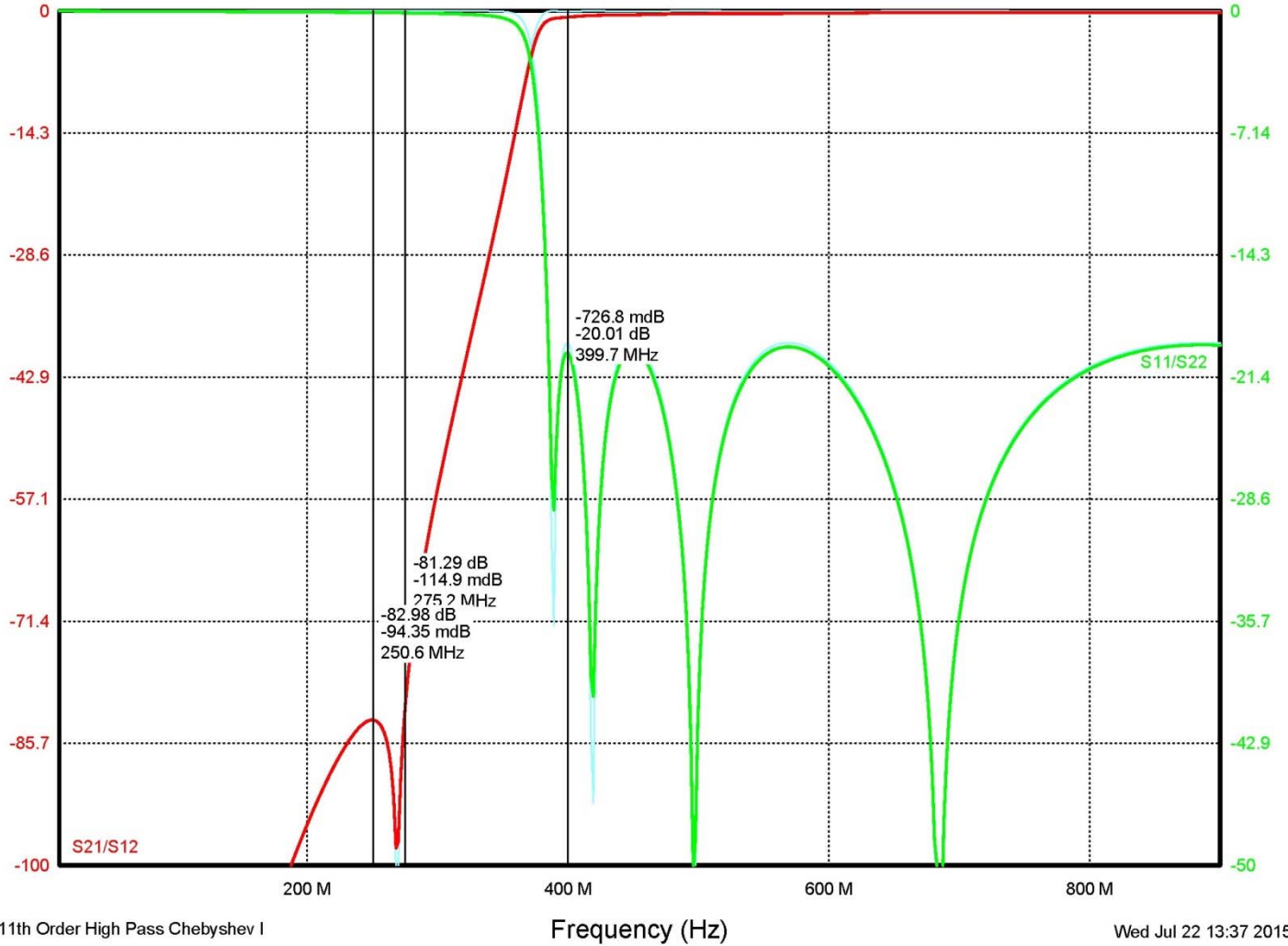

Note: This is a simulation plot. Actual results may differ once the product is implemented.