


Relay, 1 changeover contact, hard gold-plated, 12 V DC, can be used with 24 V AC/DC, complete unit

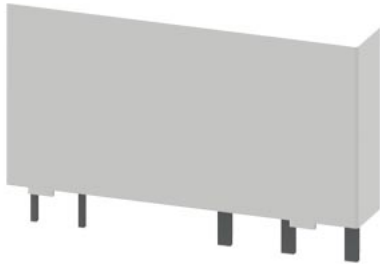

protection class IP	IP00
Substance Prohibittance (Date)	07/01/2006
operational current of auxiliary contacts at DC-13 at 230 V	0.1 A
ambient temperature during operation	-25 ... +55 °C

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3TX7014-7BQ02>

Cax online generator

<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3TX7014-7BQ02>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3TX7014-7BQ02>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3TX7014-7BQ02&lang=en

Characteristic: Derating

<https://support.industry.siemens.com/cs/ww/en/ps/3TX7014-7BQ02/manual>

last modified:

12/23/2020 