



Block Forks - Vinyl Insulated Butted Seam 22-18 AWG

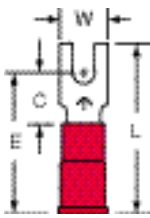


Product Number†	UPC (054007-)	Wire	Stud Size	W	C	L	E	Thickness	Barrel Length	Barrel I.D.	Maximum Insulation Diameter	Terminals per Case
		Range (AWG)										
MVU18-4FB/SK	02253	22-18	4	0.25	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000
MVU18-6FB/SK	01218	22-18	6	0.25	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000
MVU18-6FBK	01219	22-18	6	0.30	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000
MVU18-8FBK	01220	22-18	8	0.30	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000
MVU18-10FBK	01221	22-18	10	0.30	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000




MVU18-4FB/S
Stud Size: 4
Wire Range: 22-18

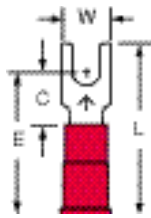


MVU18-6FB/S
Stud Size: 6
Wire Range: 22-18

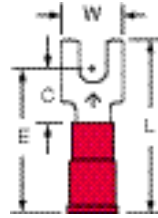

MVU18-6FB
Stud Size: 6
Wire Range: 22-18

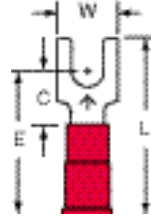

MVU18-8FB
Stud Size: 8
Wire Range: 22-18

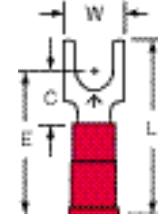

MVU18-10FB
Stud Size: 10
Wire Range: 22-18