




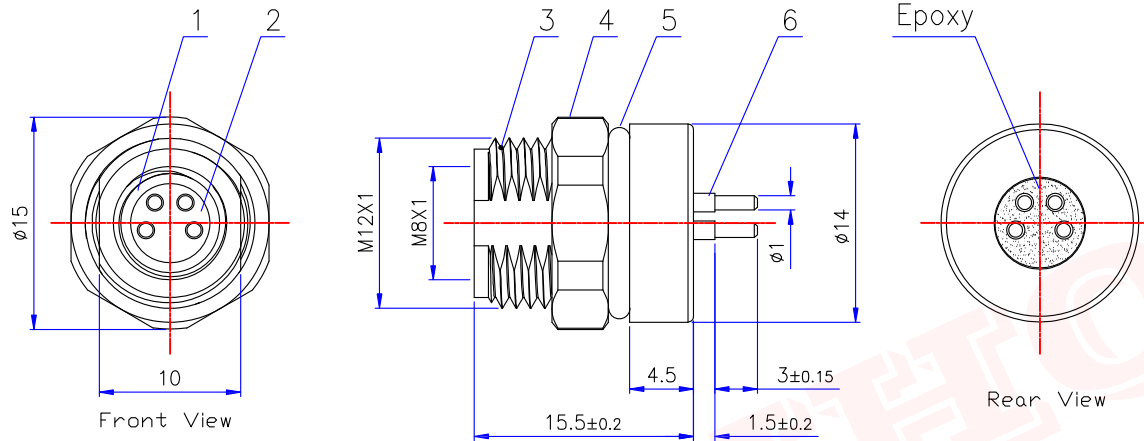

Product NO.		RHT-634-1346			
ISSUE	DESCRIPTION	DWN	DATE	APPROVEN	
R1.0	First issue	Gavin	2020/01/09	JIM. KING	

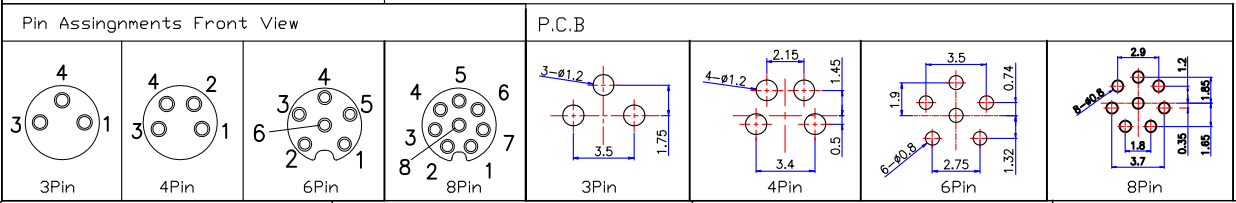

- NOTES:
- Rated voltage/current: 3pin: 60V/3A
4pin: 60V/3A
6pin: 30V/1A
 - Withstanding voltage: 3,4pin: AC850V/1 Min
6pin: AC650V/1 Min
 - Levels of protection: IP67
 - Connection mode: Soldering
 - Operating temperature: -20°C ~ +85°C
 - RoHS Compliance

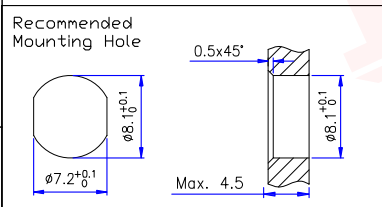

6	Contacts	Brass	Gold	3-8
5	0-Ring	Rubber		1
4	Nut M12*1	Brass	Nickel	1
3	Body	Brass	Nickel	1
2	Insulator	PA66	Black	1
1	0-Ring	Rubber		1
NO	Description	Material	Finish	Qty

-TOLERANCES- UNLESS OTHERWISE SPECIFIED	RENHOTECH www.renhotech.com		RENHOTECH GROUP			
	PART DESCRIPTION: Circular Panel Mount, Female, M8, Front Mount, DIP		P/N: RHT-634-1346			
UNLESS OTHERWISE SPECIFIED TOLERANCES FOR MILLIMETERS ARE: 0.5 - 8mm ± 0.20mm 8 - 30mm ± 0.25mm 30 - 120mm ± 0.30mm	Appr: JIM. KING	Date	Scale	Unit	Type	Page
	Draw: Gavin	2020.01.09	Free	MM	Z	1/1