





Product NO.		RHT-634-1355		
ISSUE	DESCRIPTION	DWN	DATE	APPROVEN
RL.0	First issue	Gavin	2020/08/27	JIM. KING

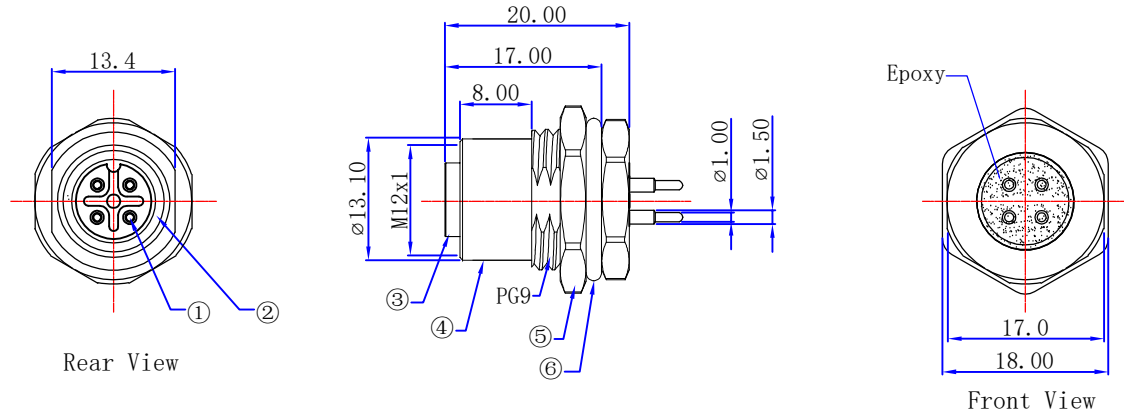

NOTES:

- Rated voltage/current : 3pin: 250V/4A
4pin: 250V/4A
5pin: 60V/4A
8pin: 30V/2A
- Levels of protection: IP67
- Connection mode: Soldering
- Operating temperature: -40°C ~+80°C
- RoHS Compliance


RECOMMENDED MOUNTING HOLE

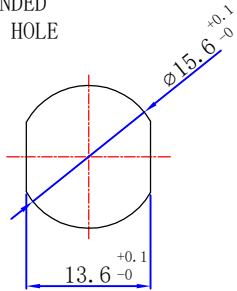

6	O-Ring	Rubber	Black	1
5	Nut M16*1.5	Brass	Nickel	1
4	Body	Brass	Nickel	1
3	Insulator	PA66	Black	1
2	O-Ring	Rubber		1
1	Contacts	Brass	Gold	3-8
NO	Description	Material	Finish	Qty

Pin Assingments Front View

P. C. B

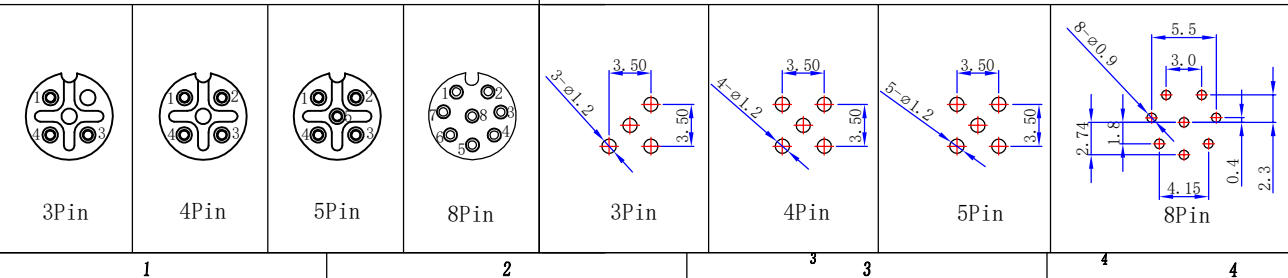

-TOLERANCES-
UNLESS OTHERWISE
SPECIFIED



UNLESS OTHERWISE SPECIFIED
TOLERANCES FOR MILLIMETERS ARE:
0.5 - 8mm ± 0.20mm
8 - 30mm ± 0.25mm
30 - 120mm ± 0.30mm

PART DESCRIPTION: Circular Panel Mount, Female, M12, Front, DIP					
Appr: JIM. KING	P/N: RHT-634-1355				
Check:	Date	Scale	Unit	Type	Page
Draw: Gavin	2020.08.27	Free	MM	Z	1/1