


REV. 1 4/8/99
DCO 102124

COIL: @ 25°C
 RESISTANCE 7600 OHMS ± 10%
 NOMINAL VOLTAGE 120.0 VDC
 MUST OPERATE 65.0 VDC
 MUST RELEASE 36.1 VDC MAX, 7.7 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 15 MS MAX.
CONTACT BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

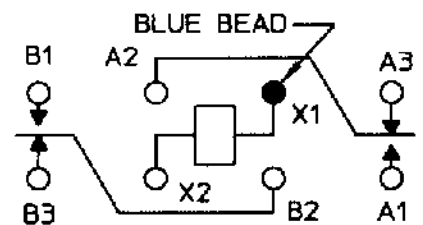

TERMINAL VIEW

CONTACT RATING: 10 AMPS 28 VDC
5 AMPS 115 VAC/400 Hz RESISTIVE
100,000 OPERATIONS

DR. R.B. 12/11/98 CK. *[Signature]*

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M5757/23-030

TYPE '07' RELAY

B07D034BE2-0135