


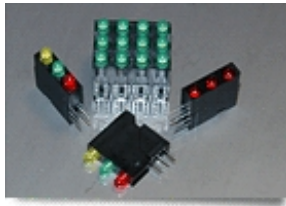

Part Number : 56403403334F



[Share](#) |

56403403334F

[564 -0x00 -xxx Datasheet](#)



This is a
RoHS Compliant Product
[To learn more click here](#)

General Description

Series	564
Configuration	3 mm Lens
Description	3 mm Tri -Level CBI 5V Y -Y-Y
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Tri-Level Housing
Viewing	Right Angle
Polarity	Cathode Right
Lens Style	Tinted, Diffused
Viewing Angle	60
LED Centerline	5.0mm

Absolute Maximum Ratings (Ta = 25 °)

Reverse Current	100 @ Vr = 5V
Derating	0.086 (mA/degC)
Reverse Voltage	5
Solder Temperature	260 for 5 secs
Operating Temperature	-40 to +85
Storage Temperature	-55 to +100

Operating Characteristics

LED Type	Integral Resistor
Color	Yellow
Peak Wave Length	585
LED Position	1,2,3
Luminous Intensity Min	3.7
Luminous Intensity Typical	12.6
Forward Voltage Typical	10
Forward Voltage Max	20
Test Current mA	20mA