

REV. 0
DCO 15877


COIL: @ 25°C	
RESISTANCE	600 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	1.5 VDC

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE 6 MS MAX
RELEASE 4 MS MAX
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

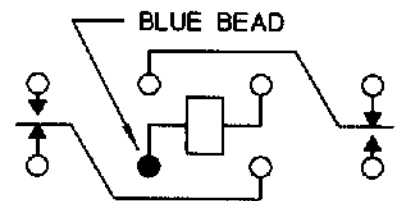

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
5 AMPS 30 VDC RESISTIVE
100,000 OPERATIONS

DR. B.D. 10/25/99 CK.GG/H 10/25/99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. HI-G
CUST. NO. ZBN-2E-126 REV.

FW5A RELAY

FW5A1296S01