

REV. 0


DCO 16568

COIL: @ 25°C	
RESISTANCE	9,100 OHMS ±10%
NOMINAL VOLTAGE	110.0 VDC
MUST OPERATE	51.0 VDC
MUST RELEASE	5.56 VDC

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	100 g's 6±1 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

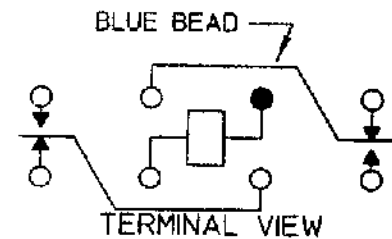

CONTACT RATING: LOW LEVEL TO  
3A 28 VDC RESISTIVE  
100,000 OPERATIONS  
MINIMUM

DR. PBB 10/19/00 CK.T.LG. 10-19-00

**CI Technologies**  
advanced control electronic solutions

CUST. C. I. I. STD.  
CUST. NO. REV.

"FW" RELAY

FW1209R00