

REV. 0
DCO 16507


COIL: @ 25°C	
RESISTANCE	675 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.5 VDC
MUST RELEASE	1.47 VDC

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6±1	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE & RELEASE TIME 5 MS MAX
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

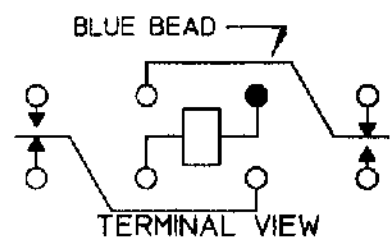

CONTACT RATING: 3 AMPS @ 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. PBB 9/26/00 CK. TLG 9-26-00



CUST.	CII STD	'FW' RELAY
CUST. NO.	REV.	

FW1111G00