

**COIL:**

RESISTANCE 330 Ω ± 10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 13.0 VDC  
 MUST RELEASE 2.0 VDC MIN.


**ENVIRONMENT:**

VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

**NOTES:**

OPERATE 13 MS MAX.  
RELEASE 5 MS MAX.  
CONTACT BOUNCE 5 MS MAX (NC)  
2 MS MAX (NO)

**CUSTOMER DATA SHEET**

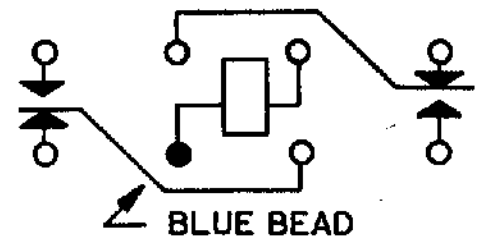

**CONTACT RATING:** 10A 30 VDC RES.,  
 10A 115 VAC 400 HZ., 6A 30 VDC  
 INDUCTIVE 100,000 OPERATIONS

DR. R.B. 7-10-91 CK. 7/10/91



CUST. HI-G  
 CUST. NO. 2T-1D-126

**TYPE "07" RELAY**

**B07B932BZ1-8011**