


COIL: @ 25°C
 RESISTANCE 675 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 1.47 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 5 MS MAX
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

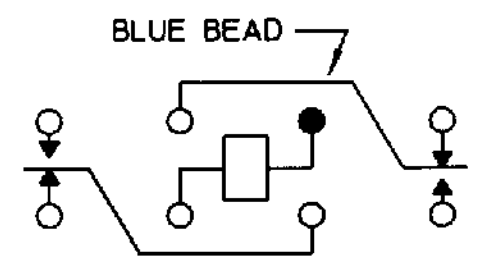

CONTACT RATING: LOW LEVEL TO
3 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. R.B. 7/8/94 CK. 7/8/94

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C.I.I. STD.
 CUST. NO. _____

TYPE "RP" RELAY

RP7633G4