

REV. 0

DCO 15971


COIL: @ 25°C	
RESISTANCE	140 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	6.3 VDC
MUST RELEASE	0.75 VDC

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE 5.0 MS MAX.  
 RELEASE 5.0 MS MAX.  
 CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

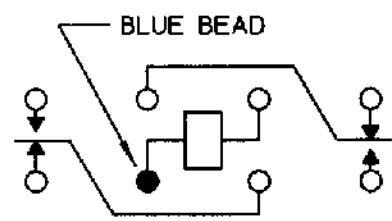

CONTACT RATING: LOW LEVEL TO 5A  
 30 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 12/10/99 CK. 69H 12/10/99



CUST. HI-G  
 CUST. NO. 2BN-4D-112 REV.

FW5A RELAY

FW5A1367S01