


COIL: @ 25°C
 RESISTANCE 90 OHMS ± 10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 6.7 VDC
 MUST RELEASE 1.0 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 13 MS MAX.
RELEASE TIME 5 MS MAX.
CONTACT BOUNCE 5 MS MAX. (NC)
2 MS MAX. (NO)

CUSTOMER DATA SHEET

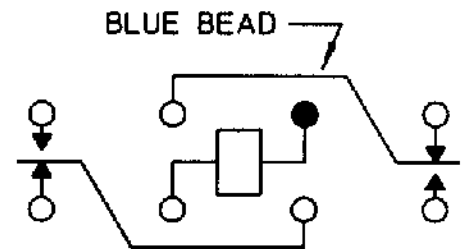

CONTACT RATING: 10 AMPS 30 VDC RES.
10 AMPS 115 VAC 400 HZ, 6A 30 VDC
INDUCTIVE 100,000 OPERATIONS

DR. R.B. 12/20/94 *CK/20/PA*

COMMUNICATIONS INSTRUMENTS, INC.

CUST. HI-G
 CUST. NO. 2T-2A-112

TYPE '07' RELAY

B07B035BZ1-8019