

REV. B
DCO 300825


TOLERANCES $\pm .010$ " - UNLESS OTHERWISE SPECIFIED

| | |
|-----------------|----------------------------|
| COIL: @ 25°C | |
| RESISTANCE | 400 OHMS $\pm 10\%$ |
| NOMINAL VOLTAGE | 28 VDC |
| MUST OPERATE | 13.5 VDC MAX. |
| MUST RELEASE | 5.5 VDC MAX., 2.3 VDC MIN. |

| | |
|--------------|---------------------------|
| ENVIRONMENT: | |
| VIBRATION | 70 Hz TO 3000 Hz @ 30 g's |
| SHOCK | 200 g's 6 MS. DURATION |
| TEMPERATURE | -70 °C TO +125 °C |

NOTES: OPERATE, RELEASE 6 MS MAX.
CONTACT STABILIZATION 2.5 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

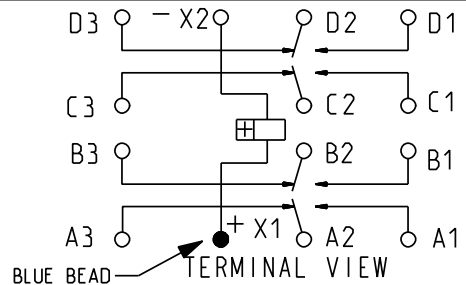

CONTACT RATING: LOW LEVEL
5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
100,000 OPERATIONS

DR. B.D. 25APR2008 CK. 5/9/08 J.M.B.

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. M83536/5-017M
CUST. NO. ---- REV. ---

TE NUMBER
6-1617760-3

CII PART NUMBER
FCB-405-0517M