

**Operation:**DIP/直立式 3.5 中型 音频连接器(SWITCH PIN)



**LTEM NO.:**PJ-358 (Series)

(L10.0×W6.0×H15.0 3.5 PHONE-JACK)



插件立式

正向操作

精密部品

带导向柱


适合环保 **RoHS**

## Technical parameter



PROJECT	LEVEL	A[better product]	B[average product]
Electrical	Contact Rating	0.5A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
Properties	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
Durable Performance	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
Storage temp.		-35℃~+75℃(Operating Temp: )	
Operating Force		IF:5~15N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

Material declaration		
No	NAME	Description
①	接觸端子#1	C5191R-H (t=0.30mm)磷銅[鍍基銀]
②	接觸端子#2	C5191R-H (t=0.25mm)磷銅[鍍基銀]
③	接觸端子#3	H62 (t=0.3mm)黃銅[鍍基銀]
④	接觸端子#4	H62 (t=0.3mm)黃銅[鍍基銀]
⑤	接觸端子#5	C5191R-H (t=0.25mm)磷銅[鍍基銀]
⑥	基座	PBT (Black)耐熱塑膠

## CIRCUIT DIAGRAM

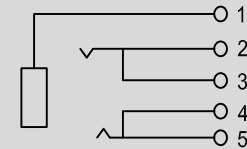

Unit:mm

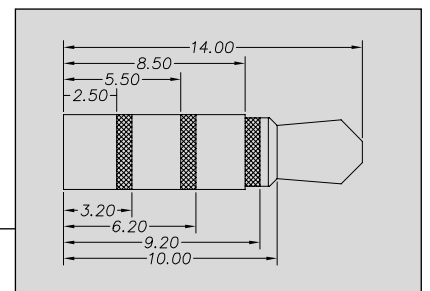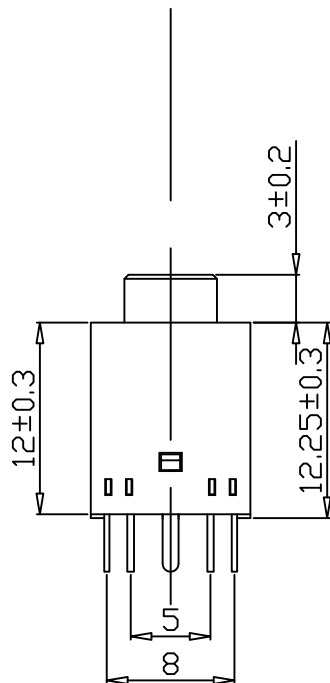

## P.C.B LAYOUT

